



BHC

Inox A2

- Selon ISO 7380
- Matière :
Inox 302/304-A2
- 6 pans creux

Info.

- Conditionnement par lot

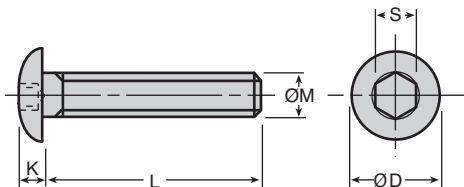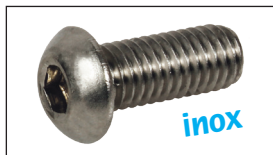

REMISES

Nb. lots	1+	2+	4+
Rem.	Prix	-20%	Sur demande

Références	Filetage		Longueur			Quantité par lot	Stock*	Prix Uni. par lot
	ØM	Pas	L	ØD	K			
BHC4-8/SS/B	M4	0,70	8	7,6	2,20	2,5	500	✓ 27,49 €
BHC4-10/SS/B	M4	0,70	10	7,6	2,20	2,5	500	✓ 33,89 €
BHC4-12/SS/B	M4	0,70	12	7,6	2,20	2,5	500	✓ 32,40 €
BHC4-16/SS/B	M4	0,70	16	7,6	2,20	2,5	500	- 20,87 €
BHC5-10/SS/B	M5	0,80	10	9,5	2,75	3,0	500	✓ 22,29 €
BHC5-12/SS/B	M5	0,80	12	9,5	2,75	3,0	500	✓ 30,97 €
BHC5-16/SS/B	M5	0,80	16	9,5	2,75	3,0	500	- 33,80 €
BHC5-20/SS/B	M5	0,80	20	9,5	2,75	3,0	500	✓ 36,98 €
BHC6-12/SS/B	M6	1,00	12	10,5	3,30	4,0	500	✓ 34,34 €
BHC6-16/SS/B	M6	1,00	16	10,5	3,30	4,0	500	- 41,07 €
BHC6-20/SS/B	M6	1,00	20	10,5	3,30	4,0	500	✓ 47,61 €
BHC6-25/SS/B	M6	1,00	25	10,5	3,30	4,0	500	- 67,04 €
BHC8-16/SS/B	M8	1,25	16	14,0	4,40	5,0	200	✓ 37,03 €
BHC8-20/SS/B	M8	1,25	20	14,0	4,40	5,0	200	✓ 35,40 €
BHC8-25/SS/B	M8	1,25	25	14,0	4,40	5,0	200	- 50,10 €
BHC8-30/SS/B	M8	1,25	30	14,0	4,40	5,0	200	- 56,38 €

*Dans la limite du disponible - Dimensions en mm