

Goupille clip à anneau






GCA

Acier zingué

- Goupille économique
- Matière :
acier zingué bichromaté
- Conditionnées par lot

Avantages

- Montage/démontage manuel

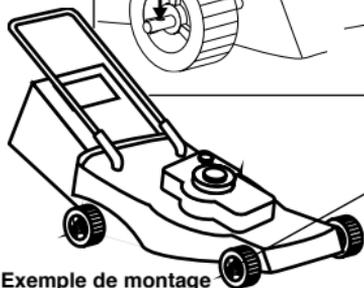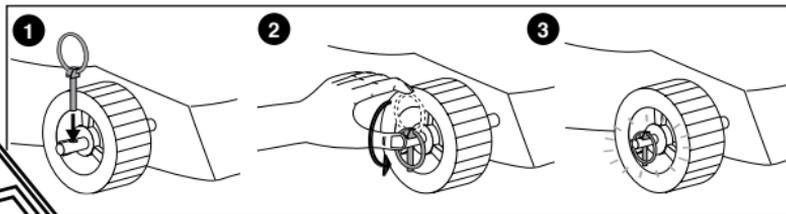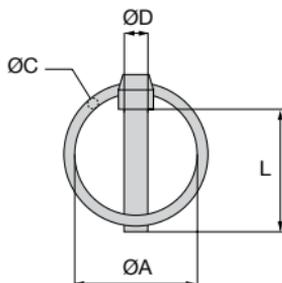

Exemple de montage

REMISES

Qté	1+	5+	10+	21+
Rem.	Prix	-10%	-20%	Sur demande



Références	ØD	L	ØA	ØC	Masse au 100 (kg)	Quantité par lot	Stock*	Prix Uni 1 à 4
GCA4.5-3/B	4,5	42	34	3	1,31	100	✓	46,47 €
GCA6-3.5/B	6	42	41	3,5	2,30	50	✓	23,90 €
GCA7-3.5/B	7	42	41	3,5	2,65	50	✓	24,28 €
GCA8-3.5/B	8	42	41	3,5	2,91	50	✓	28,04 €
GCA9-3.5/B	9	42	41	3,5	3,55	50	✓	30,22 €
GCA10-3.5/B	10	42	41	3,5	4,27	50	✓	31,73 €
GCA11-3.5/B	11	42	41	3,5	4,77	50	-	33,31 €

*Dans la limite du disponible - Dimensions en mm


- Goupille économique
- Matière :
Acier zingué bichromaté
- Conditionnée par lot

Avantages


- Montage / démontage manuel

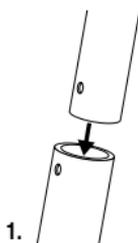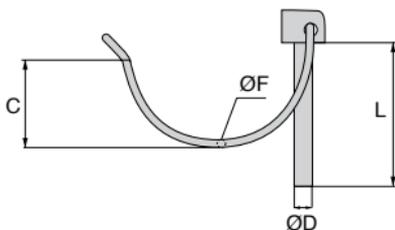

1.

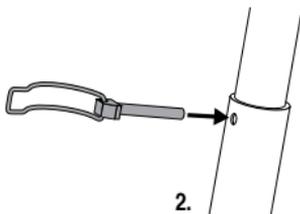

2.

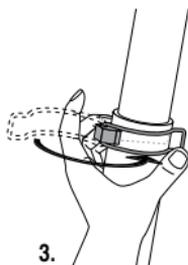

3.



4.

REMISES

Qté	1+	5+	10+	21+
Rem. Prix	-10%	-20%	Sur demande	Sur demande

Références	ØD	L	C	ØF	Pour tube ØT	Masse au 100 (kg)	Qté par lot	Stock*	Prix Uni. 1 à 4
GCT4.5-40/B	4,5	40	18	3	38-39	1,7	50	✓	29,50 €
GCT6-32/B	6	32	18	3	30-31	2,0	50	✓	31,45 €
GCT6-45/B	6	45	22	3	43-44	2,6	50	✓	34,02 €
GCT8-40/B	8	40	18	3	38-39	3,5	50	✓	37,29 €
GCT8-45/B	8	45	22	3	43-44	3,8	50	✓	39,82 €
GCT8-50/B	8	50	25	3	48-49	4,0	50	✓	42,28 €
GCT8-60/B	8	60	28	3	58-59	4,3	50	✓	46,18 €
GCT10-40/B	10	40	18	3,2	37-38	5,0	25	✓	25,17 €
GCT10-50/B	10	50	25	3,2	47-48	5,8	25	✓	27,94 €
GCT10-60/B	10	60	28	3,2	57-58	6,3	25	✓	31,00 €

*Dans la limite du disponible - Dimensions en mm