


# Vis tête hexagonale **DIN933**

Laiton

VTH<sub>BR</sub>

- Vis selon DIN933
- Matière :  
Laiton

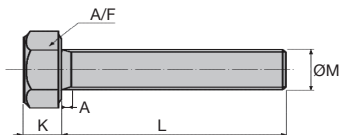

## REMISES

|      |      |      |             |
|------|------|------|-------------|
| Qté  | 1+   | 6+   | 11+         |
| Rem. | Prix | -10% | Sur demande |

| Références   | ØM | Pas  | L  | A (max) | K   | A/F surplat | Qté/lot | Prix Uni. 1 à 5 |
|--------------|----|------|----|---------|-----|-------------|---------|-----------------|
| VTH4-10/BR/B | M4 | 0,70 | 10 | 2,10    | 2,8 | 7           | 100     | 9,68 €          |
| VTH4-16/BR/B | M4 | 0,70 | 16 | 2,10    | 2,8 | 7           | 100     | 11,31 €         |
| VTH4-20/BR/B | M4 | 0,70 | 20 | 2,10    | 2,8 | 7           | 100     | 13,92 €         |
| VTH4-25/BR/B | M4 | 0,70 | 25 | 2,10    | 2,8 | 7           | 100     | 15,54 €         |
| VTH4-30/BR/B | M4 | 0,70 | 30 | 2,10    | 2,8 | 7           | 100     | 17,80 €         |
| VTH5-10/BR/B | M5 | 0,80 | 10 | 2,40    | 3,5 | 8           | 100     | 13,33 €         |
| VTH5-16/BR/B | M5 | 0,80 | 16 | 2,40    | 3,5 | 8           | 100     | 19,16 €         |
| VTH5-20/BR/B | M5 | 0,80 | 20 | 2,40    | 3,5 | 8           | 100     | 20,95 €         |
| VTH5-25/BR/B | M5 | 0,80 | 25 | 2,40    | 3,5 | 8           | 100     | 22,27 €         |
| VTH5-30/BR/B | M5 | 0,80 | 30 | 2,40    | 3,5 | 8           | 100     | 27,09 €         |
| VTH5-40/BR/B | M5 | 0,80 | 40 | 2,40    | 3,5 | 8           | 100     | 34,30 €         |
| VTH6-10/BR/B | M6 | 1,00 | 10 | 3,00    | 4,0 | 10          | 100     | 22,67 €         |
| VTH6-20/BR/B | M6 | 1,00 | 20 | 3,00    | 4,0 | 10          | 100     | 30,24 €         |
| VTH6-25/BR/B | M6 | 1,00 | 25 | 3,00    | 4,0 | 10          | 100     | 35,52 €         |
| VTH6-30/BR/B | M6 | 1,00 | 30 | 3,00    | 4,0 | 10          | 100     | 39,19 €         |
| VTH6-40/BR/B | M6 | 1,00 | 40 | 3,00    | 4,0 | 10          | 100     | 46,53 €         |
| VTH6-50/BR/B | M6 | 1,00 | 50 | 3,00    | 4,0 | 10          | 100     | 58,10 €         |
| VTH8-16/BR/B | M8 | 1,25 | 16 | 3,75    | 5,3 | 13          | 100     | 56,01 €         |
| VTH8-20/BR/B | M8 | 1,25 | 20 | 3,75    | 5,3 | 13          | 100     | 64,16 €         |
| VTH8-25/BR/B | M8 | 1,25 | 25 | 3,75    | 5,3 | 13          | 100     | 71,12 €         |
| VTH8-30/BR/B | M8 | 1,25 | 30 | 3,75    | 5,3 | 13          | 100     | 74,76 €         |
| VTH8-40/BR/B | M8 | 1,25 | 40 | 3,75    | 5,3 | 13          | 100     | 115,66 €        |
| VTH8-50/BR/B | M8 | 1,25 | 50 | 3,75    | 5,3 | 13          | 100     | 98,46 €         |
| VTH8-60/BR/B | M8 | 1,25 | 60 | 3,75    | 5,3 | 13          | 100     | 122,58 €        |

Dimensions en mm

# Vis tête hexagonale **DIN 933**

Stock


## VTH

## Acier zingué classe 8.8

- Vis selon DIN 933
- Filetage total
- Matière :  
Acier zingué classe 8.8
- Caractéristiques mécaniques conformes  
à la norme ISO898-1

### Info.

- Conditionnement par lot

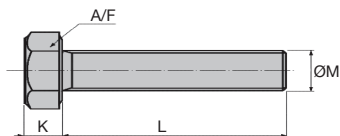

### REMISES

| Qté       | 1+   | 2+          | 4+ |
|-----------|------|-------------|----|
| Rem. Prix | -20% | Sur demande |    |

| Références | ØM | Pas  |    | K    | A/F<br>surplats | Qté/lot | Stock* | Prix Uni. |
|------------|----|------|----|------|-----------------|---------|--------|-----------|
|            |    | P    | L  |      |                 |         |        |           |
| VTH4-10/B  | M4 | 0,70 | 10 | 2,92 | 7,0             | 500     | -      | 10,07 €   |
| VTH4-12/B  | M4 | 0,70 | 12 | 2,92 | 7,0             | 500     | -      | 11,03 €   |
| VTH4-16/B  | M4 | 0,70 | 16 | 2,92 | 7,0             | 500     | -      | 13,07 €   |
| VTH4-20/B  | M4 | 0,70 | 20 | 2,92 | 7,0             | 500     | ✓      | 39,55 €   |
| VTH4-25/B  | M4 | 0,70 | 25 | 2,92 | 7,0             | 500     | -      | 17,39 €   |
| VTH4-30/B  | M4 | 0,70 | 30 | 2,92 | 7,0             | 500     | -      | 19,74 €   |
| VTH4-35/B  | M4 | 0,70 | 35 | 2,92 | 7,0             | 200     | -      | 12,32 €   |
| VTH4-40/B  | M4 | 0,70 | 40 | 2,92 | 7,0             | 200     | -      | 13,82 €   |
| VTH5-10/B  | M5 | 0,80 | 10 | 3,65 | 8,0             | 500     | ✓      | 18,94 €   |
| VTH5-12/B  | M5 | 0,80 | 12 | 3,65 | 8,0             | 500     | -      | 11,23 €   |
| VTH5-16/B  | M5 | 0,80 | 16 | 3,65 | 8,0             | 500     | -      | 13,10 €   |
| VTH5-20/B  | M5 | 0,80 | 20 | 3,65 | 8,0             | 500     | ✓      | 25,52 €   |
| VTH5-25/B  | M5 | 0,80 | 25 | 3,65 | 8,0             | 500     | -      | 17,39 €   |
| VTH5-30/B  | M5 | 0,80 | 30 | 3,65 | 8,0             | 500     | -      | 19,80 €   |
| VTH5-35/B  | M5 | 0,80 | 35 | 3,65 | 8,0             | 200     | -      | 8,88 €    |
| VTH5-40/B  | M5 | 0,80 | 40 | 3,65 | 8,0             | 200     | -      | 9,84 €    |
| VTH5-45/B  | M5 | 0,80 | 45 | 3,65 | 8,0             | 200     | -      | 11,38 €   |
| VTH5-50/B  | M5 | 0,80 | 50 | 3,65 | 8,0             | 200     | -      | 12,65 €   |

\*Dans la limite du disponible - Dimensions en mm

## REMISES

|      |           |             |    |
|------|-----------|-------------|----|
| Qté  | 1+        | 2+          | 4+ |
| Rem. | Prix -20% | Sur demande |    |

| Références  | ØM  | Pas<br>P | L   | K    | A/F<br>surplats | Qté/lot | Stock* | Prix Uni. |
|-------------|-----|----------|-----|------|-----------------|---------|--------|-----------|
| VTH6-10/B   | M6  | 1,00     | 10  | 4,15 | 10,0            | 500     | -      | 14,97 €   |
| VTH6-16/B   | M6  | 1,00     | 16  | 4,15 | 10,0            | 500     | ✓      | 27,35 €   |
| VTH6-20/B   | M6  | 1,00     | 20  | 4,15 | 10,0            | 500     | ✓      | 33,94 €   |
| VTH6-25/B   | M6  | 1,00     | 25  | 4,15 | 10,0            | 500     | ✓      | 35,48 €   |
| VTH6-30/B   | M6  | 1,00     | 30  | 4,15 | 10,0            | 500     | ✓      | 40,25 €   |
| VTH6-40/B   | M6  | 1,00     | 40  | 4,15 | 10,0            | 200     | ✓      | 19,24 €   |
| VTH6-50/B   | M6  | 1,00     | 50  | 4,15 | 10,0            | 200     | ✓      | 24,45 €   |
| VTH6-60/B   | M6  | 1,00     | 60  | 4,15 | 10,0            | 200     | -      | 24,44 €   |
| VTH8-20/B   | M8  | 1,25     | 20  | 5,45 | 13,0            | 200     | ✓      | 25,63 €   |
| VTH8-30/B   | M8  | 1,25     | 30  | 5,45 | 13,0            | 200     | ✓      | 29,51 €   |
| VTH8-40/B   | M8  | 1,25     | 40  | 5,45 | 13,0            | 100     | ✓      | 19,00 €   |
| VTH8-50/B   | M8  | 1,25     | 50  | 5,45 | 13,0            | 100     | ✓      | 23,50 €   |
| VTH8-60/B   | M8  | 1,25     | 60  | 5,45 | 13,0            | 100     | -      | 26,27 €   |
| VTH8-70/B   | M8  | 1,25     | 70  | 5,45 | 13,0            | 100     | -      | 29,00 €   |
| VTH8-80/B   | M8  | 1,25     | 80  | 5,45 | 13,0            | 100     | -      | 32,06 €   |
| VTH10-20/B  | M10 | 1,50     | 20  | 6,58 | 17,0            | 200     | ✓      | 33,72 €   |
| VTH10-30/B  | M10 | 1,50     | 30  | 6,58 | 17,0            | 200     | -      | 29,33 €   |
| VTH10-40/B  | M10 | 1,50     | 40  | 6,58 | 17,0            | 100     | ✓      | 29,73 €   |
| VTH10-50/B  | M10 | 1,50     | 50  | 6,58 | 17,0            | 100     | ✓      | 45,53 €   |
| VTH10-60/B  | M10 | 1,50     | 60  | 6,58 | 17,0            | 50      | -      | 11,86 €   |
| VTH10-70/B  | M10 | 1,50     | 70  | 6,58 | 17,0            | 50      | ✓      | 13,44 €   |
| VTH10-80/B  | M10 | 1,50     | 80  | 6,58 | 17,0            | 50      | -      | 14,91 €   |
| VTH10-100/B | M10 | 1,50     | 100 | 6,58 | 17,0            | 50      | ✓      | 31,17 €   |
| VTH12-20/B  | M12 | 1,75     | 20  | 7,68 | 19,0            | 100     | ✓      | 18,02 €   |
| VTH12-35/B  | M12 | 1,75     | 35  | 7,68 | 19,0            | 100     | ✓      | 41,01 €   |
| VTH12-45/B  | M12 | 1,75     | 45  | 7,68 | 19,0            | 100     | -      | 28,20 €   |
| VTH12-55/B  | M12 | 1,75     | 55  | 7,68 | 19,0            | 50      | -      | 15,94 €   |
| VTH12-60/B  | M12 | 1,75     | 60  | 7,68 | 19,0            | 50      | -      | 16,70 €   |
| VTH12-70/B  | M12 | 1,75     | 70  | 7,68 | 19,0            | 50      | -      | 19,80 €   |
| VTH12-80/B  | M12 | 1,75     | 80  | 7,68 | 19,0            | 50      | -      | 21,92 €   |
| VTH12-100/B | M12 | 1,75     | 100 | 7,68 | 19,0            | 50      | -      | 26,25 €   |

\*Dans la limite du disponible - Dimensions en mm