


# Vis tête hexagonale **DIN933**

Laiton

VTH<sub>BR</sub>

- Vis selon DIN933
- Matière :  
Laiton

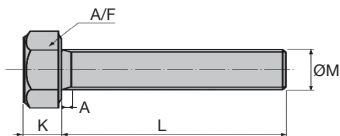

## REMISES

Qté	1+	6+	11+
Rem.	Prix	-10%	Sur demande

Références	ØM	Pas	L	A (max)	K	A/F surplat	Qté/lot	Prix Uni. 1 à 5
VTH4-10/BR/B	M4	0,70	10	2,10	2,8	7	100	9,68 €
VTH4-16/BR/B	M4	0,70	16	2,10	2,8	7	100	11,31 €
VTH4-20/BR/B	M4	0,70	20	2,10	2,8	7	100	13,92 €
VTH4-25/BR/B	M4	0,70	25	2,10	2,8	7	100	15,54 €
VTH4-30/BR/B	M4	0,70	30	2,10	2,8	7	100	17,80 €
VTH5-10/BR/B	M5	0,80	10	2,40	3,5	8	100	13,33 €
VTH5-16/BR/B	M5	0,80	16	2,40	3,5	8	100	19,16 €
VTH5-20/BR/B	M5	0,80	20	2,40	3,5	8	100	20,95 €
VTH5-25/BR/B	M5	0,80	25	2,40	3,5	8	100	22,27 €
VTH5-30/BR/B	M5	0,80	30	2,40	3,5	8	100	27,09 €
VTH5-40/BR/B	M5	0,80	40	2,40	3,5	8	100	34,30 €
VTH6-10/BR/B	M6	1,00	10	3,00	4,0	10	100	22,67 €
VTH6-20/BR/B	M6	1,00	20	3,00	4,0	10	100	30,24 €
VTH6-25/BR/B	M6	1,00	25	3,00	4,0	10	100	35,52 €
VTH6-30/BR/B	M6	1,00	30	3,00	4,0	10	100	39,19 €
VTH6-40/BR/B	M6	1,00	40	3,00	4,0	10	100	46,53 €
VTH6-50/BR/B	M6	1,00	50	3,00	4,0	10	100	58,10 €
VTH8-16/BR/B	M8	1,25	16	3,75	5,3	13	100	56,01 €
VTH8-20/BR/B	M8	1,25	20	3,75	5,3	13	100	64,16 €
VTH8-25/BR/B	M8	1,25	25	3,75	5,3	13	100	71,12 €
VTH8-30/BR/B	M8	1,25	30	3,75	5,3	13	100	74,76 €
VTH8-40/BR/B	M8	1,25	40	3,75	5,3	13	100	115,66 €
VTH8-50/BR/B	M8	1,25	50	3,75	5,3	13	100	98,46 €
VTH8-60/BR/B	M8	1,25	60	3,75	5,3	13	100	122,58 €

Dimensions en mm

# Vis tête hexagonale **DIN 933**

Stock


## VTH

## Acier zingué classe 8.8

- Vis selon DIN 933
- Filetage total
- Matière :  
Acier zingué classe 8.8
- Caractéristiques mécaniques conformes  
à la norme ISO898-1

### Info.

- Conditionnement par lot

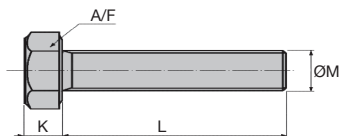

### REMISES

Qté	1+	2+	4+
Rem. Prix	-20%	Sur demande	

Références	ØM	Pas		K	A/F surplats	Qté/lot	Stock*	Prix Uni.
		P	L					
VTH4-10/B	M4	0,70	10	2,92	7,0	500	-	10,07 €
VTH4-12/B	M4	0,70	12	2,92	7,0	500	-	11,03 €
VTH4-16/B	M4	0,70	16	2,92	7,0	500	-	13,07 €
VTH4-20/B	M4	0,70	20	2,92	7,0	500	✓	39,55 €
VTH4-25/B	M4	0,70	25	2,92	7,0	500	-	17,39 €
VTH4-30/B	M4	0,70	30	2,92	7,0	500	-	19,74 €
VTH4-35/B	M4	0,70	35	2,92	7,0	200	-	12,32 €
VTH4-40/B	M4	0,70	40	2,92	7,0	200	-	13,82 €
VTH5-10/B	M5	0,80	10	3,65	8,0	500	✓	18,94 €
VTH5-12/B	M5	0,80	12	3,65	8,0	500	-	11,23 €
VTH5-16/B	M5	0,80	16	3,65	8,0	500	-	13,10 €
VTH5-20/B	M5	0,80	20	3,65	8,0	500	✓	25,52 €
VTH5-25/B	M5	0,80	25	3,65	8,0	500	-	17,39 €
VTH5-30/B	M5	0,80	30	3,65	8,0	500	-	19,80 €
VTH5-35/B	M5	0,80	35	3,65	8,0	200	-	8,88 €
VTH5-40/B	M5	0,80	40	3,65	8,0	200	-	9,84 €
VTH5-45/B	M5	0,80	45	3,65	8,0	200	-	11,38 €
VTH5-50/B	M5	0,80	50	3,65	8,0	200	-	12,65 €

\*Dans la limite du disponible - Dimensions en mm

## REMISES

Qté	1+	2+	4+
Rem.	Prix -20%		Sur demande

Références	ØM	Pas P	L	K	A/F surplats	Qté/lot	Stock*	Prix Uni.
VTH6-10/B	M6	1,00	10	4,15	10,0	500	-	14,97 €
VTH6-16/B	M6	1,00	16	4,15	10,0	500	✓	27,35 €
VTH6-20/B	M6	1,00	20	4,15	10,0	500	✓	33,94 €
VTH6-25/B	M6	1,00	25	4,15	10,0	500	✓	35,48 €
VTH6-30/B	M6	1,00	30	4,15	10,0	500	✓	40,25 €
VTH6-40/B	M6	1,00	40	4,15	10,0	200	✓	19,24 €
VTH6-50/B	M6	1,00	50	4,15	10,0	200	✓	24,45 €
VTH6-60/B	M6	1,00	60	4,15	10,0	200	-	24,44 €
VTH8-20/B	M8	1,25	20	5,45	13,0	200	✓	25,63 €
VTH8-30/B	M8	1,25	30	5,45	13,0	200	✓	29,51 €
VTH8-40/B	M8	1,25	40	5,45	13,0	100	✓	19,00 €
VTH8-50/B	M8	1,25	50	5,45	13,0	100	✓	23,50 €
VTH8-60/B	M8	1,25	60	5,45	13,0	100	-	26,27 €
VTH8-70/B	M8	1,25	70	5,45	13,0	100	-	29,00 €
VTH8-80/B	M8	1,25	80	5,45	13,0	100	-	32,06 €
VTH10-20/B	M10	1,50	20	6,58	17,0	200	✓	33,72 €
VTH10-30/B	M10	1,50	30	6,58	17,0	200	-	29,33 €
VTH10-40/B	M10	1,50	40	6,58	17,0	100	✓	29,73 €
VTH10-50/B	M10	1,50	50	6,58	17,0	100	✓	45,53 €
VTH10-60/B	M10	1,50	60	6,58	17,0	50	-	11,86 €
VTH10-70/B	M10	1,50	70	6,58	17,0	50	✓	13,44 €
VTH10-80/B	M10	1,50	80	6,58	17,0	50	-	14,91 €
VTH10-100/B	M10	1,50	100	6,58	17,0	50	✓	31,17 €
VTH12-20/B	M12	1,75	20	7,68	19,0	100	✓	18,02 €
VTH12-35/B	M12	1,75	35	7,68	19,0	100	✓	41,01 €
VTH12-45/B	M12	1,75	45	7,68	19,0	100	-	28,20 €
VTH12-55/B	M12	1,75	55	7,68	19,0	50	-	15,94 €
VTH12-60/B	M12	1,75	60	7,68	19,0	50	-	16,70 €
VTH12-70/B	M12	1,75	70	7,68	19,0	50	-	19,80 €
VTH12-80/B	M12	1,75	80	7,68	19,0	50	-	21,92 €
VTH12-100/B	M12	1,75	100	7,68	19,0	50	-	26,25 €

\*Dans la limite du disponible - Dimensions en mm