

# AT-type timing belt **per metre**



Pitch

**AT5**

**AT10**


Steel cored polyurethane

SINGLE-SIDED



Din 7721

- 2nd generation metric profile
- Transmits a greater load
- Pitch 5 or 10mm
- For linear movements
- Secured using rigid connecting plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length  $\pm 0.8\text{mm}/1000\text{mm}$
- Efficiency: up to 98%
- Oil-resistant
- Low noise
- Resists stretching

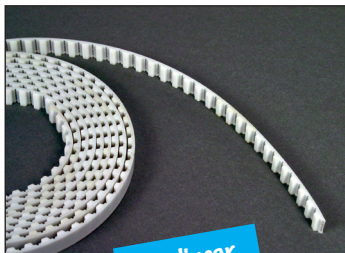

For linear positioning

## Uses


- For reciprocating movements

## Accessories

- Connecting plate AT.../P


## Info.

- Min. length: 1000mm
  - Supplied in multiples of 1 metre
  - When ordering, add the length (L) and the width (I) to the part number (AT5M/L/I).
- E.g.: AT5M/1000/16

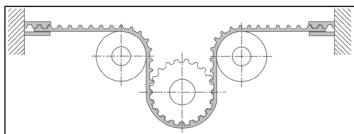


Typical application

AT5M

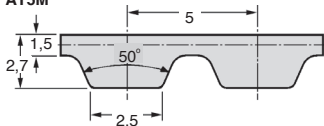

AT10M

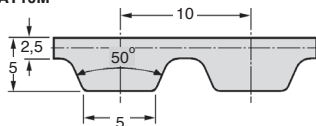

## DISCOUNTS

| Qty   | 1+   | 6+  | 20+        |
|-------|------|-----|------------|
| Disc. | List | -7% | On request |

| Part number | Pitch | Price 1 to 5, per metre for width |         |         |         |         |
|-------------|-------|-----------------------------------|---------|---------|---------|---------|
|             |       | 10mm                              | 16mm    | 25mm    | 32mm    | 50mm    |
| AT5M        | AT5   | 30,21 €                           | 35,90 € | 67,30 € | -       | -       |
| AT10M       | AT10  | -                                 | -       | 58,04 € | 74,08 € | 82,33 € |

Dimensions in mm