

# Hi-Klik™ detent hinge

## CHAK

## Adjustable in 30° steps

- Hinge that allows a panel or door to be opened in 30° steps and to maintain the position without the use of any additional support.

- Screw-on front hinge
- Reduced size
- Max opening angle 180°  
(up to 270° depending on mounting arrangement)
- Working temp range: -30 to 70 °C
- Installed using DIN912 screws (not supplied)
- Materials:

Winds: Black anodised aluminium

Positioning mechanism: raw sintered steel

Washers: Black PA polyamide

Screw/nut: stainless steel


- Max N° of opening cycles: 30,000  
(with 20% torque loss)

### Application

- Machine covers
- Industrial displays and LCD screens



### Info

- The retaining torque is factory set and cannot be modified by the user

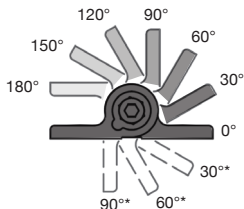

### Angular indexing positions

\*given as a guide only, will depend on panel thickness

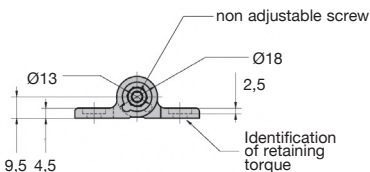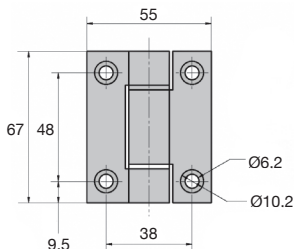

### DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-5%	On request

Part number	Panel holding torque**(Nm)	Required torque to move**(Nm)	Weight (g)	Stock*	Price each 1 to 5
CHAK6755-L-AN	0,8	1,8	106	-	57,30 €
CHAK6755-M-AN	1,2	2,5	106	✓	62,39 €
CHAK6755-H-AN	2,0	3,2	106	✓	68,80 €

\*\*Tolerance +/-20% - \*Depending on availability - Dimensions in mm

**HPC**

WEB  
04/2020

www.hpceurope.com

Tél: 0 825 88 5000

Service 0,15 €/min + prix appel