

Moulded plastic spur gear




Module 2.5

Nylon 6 **moulded**


- Moulded parts
- Pressure angle 20°
- Material:
Nylon 6, Reinforced with 30% glass fibres

Options

- Alternative number of teeth, a datasheet is available from www.hpceurope.com in PDF format
- HPC are unable to modify these parts. For parts that can be modified to order, please see the ZG and ZPG ranges.

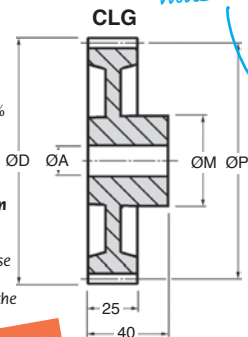

A: Pre-bored hole must be finished

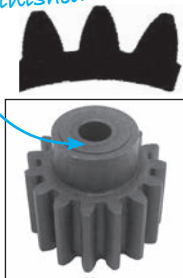

Economy range

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-10%	-15%	-25%	On request

Part number	No. of teeth	Outside ØD	PCD ØP	Boss ØM	Bore ØA	Stock*	Price each 1 to 9
CLG2.5-12	12	35,00	30,00	22	8	✓	6,29 €
CLG2.5-14	14	40,00	35,00	22	8	-	On request
CLG2.5-15	15	42,50	37,50	30	10	✓	6,29 €
CLG2.5-16	16	45,00	40,00	30	10	✓	9,12 €
CLG2.5-18	18	50,00	45,00	35	10	✓	9,12 €
CLG2.5-20	20	55,00	50,00	35	10	✓	9,12 €
CLG2.5-22	22	60,00	55,00	40	16	-	On request
CLG2.5-23	23	62,50	57,50	40	16	-	On request
CLG2.5-24	24	65,00	60,00	40	16	-	On request
CLG2.5-25	25	67,50	62,50	40	16	✓	12,50 €
CLG2.5-26	26	70,00	65,00	40	16	-	On request
CLG2.5-27	27	72,50	67,50	40	16	-	On request
CLG2.5-28	28	75,00	70,00	40	16	-	On request
CLG2.5-29	29	77,50	72,50	40	16	-	On request
CLG2.5-30	30	80,00	75,00	45	16	-	15,87 €
CLG2.5-32	32	85,00	80,00	50	16	-	On request
CLG2.5-35	35	92,50	87,50	50	16	-	18,90 €
CLG2.5-40	40	105,00	100,00	60	20	-	On request
CLG2.5-45	45	117,50	112,50	60	20	-	28,29 €
CLG2.5-50	50	130,00	125,00	60	20	✓	31,31 €
CLG2.5-57	57	147,50	142,50	60	20	-	On request
Gears available up to this size							
CLG2.5-62	62	160,00	155,00	60	25	-	On request

*Depending on availability - Dimensions in mm