
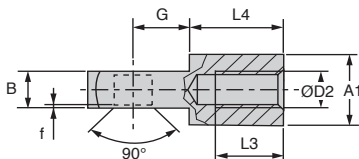
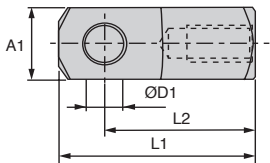


CLM CLMss

Steel or stainless steel

- Clevis link
- Threaded end piece for clevis conforming to DIN17152, short version
- Steel 11SMnPb30+C, galvanised
- Stainless steel 303

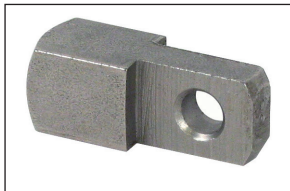

DISCOUNTS Steel

Qty	1+	10+	20+	50+
Disc.	List	-10%	-15%	On request

DISCOUNTS Stainless steel

Qty	1+	4+	10+	20+
Disc.	List	-10%	-15%	On request

Part number	ØD1 H9	ØD2	B	A1 h11	L1 +/-0,5	L2 +/-0,3	L3	L4 +/-0,2	G +/-0,5	f +/-0,2	Weight (g)	Price each 1 to 5
Steel												
CLM-4	4	M4x0,7	4	8	21	16	6	10,0	6,0	0,5	6	1,92 €
CLM-5	5	M5x0,8	5	10	26	20	8	12,5	7,5	0,5	12	1,85 €
CLM-6	6	M6x1	6	12	31	24	11	15,0	9,0	0,5	21	2,69 €
CLM-8	8	M8x1,25	8	16	42	32	14	20,0	12,0	0,5	51	3,64 €
CLM-10	10	M10x1,5	10	20	52	40	18	25,0	15,0	0,5	98	3,43 €
CLM-12	12	M12x1,75	12	24	62	48	22	30,0	18,0	0,5	168	8,05 €
CLM-16	16	M16x2	16	32	83	64	30	40,0	24,0	1,0	397	10,08 €
Stainless steel												
CLM-4/SS	4	M4x0,7	4	8	21	16	6	10,0	6,0	0,5	6	5,33 €
CLM-5/SS	5	M5x0,8	5	10	26	20	8	12,5	7,5	0,5	12	7,56 €
CLM-6/SS	6	M6x1	6	12	31	24	11	15,0	9,0	0,5	21	10,97 €
CLM-8/SS	8	M8x1,25	8	16	42	32	14	20,0	12,0	0,5	51	9,52 €
CLM-10/SS	10	M10x1,5	10	20	52	40	18	25,0	15,0	0,5	98	8,98 €
CLM-12/SS	12	M12x1,75	12	24	62	48	22	30,0	18,0	0,5	168	12,55 €
CLM-16/SS	16	M16x2	16	32	83	64	30	40,0	24,0	1,0	397	36,10 €

*Depending on availability - Dimensions in mm

Instruction guide

