

Telescopic universal ball joint

CTH

With splined ball shaft

- Needle bearings
- Max. angle of misalignment 90°
- Materials:
Body: C45 steel
Pin: Hardened steel 18NCD4




Uses

- High speed applications

Torque

- Please contact us to discuss your requirements

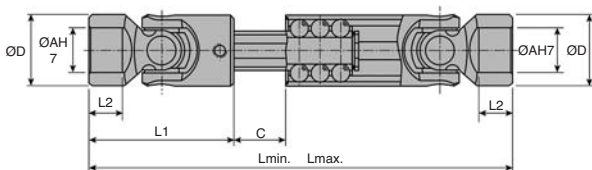

modifiable bore-size



DISCOUNTS

Qty.	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	Lmin-max	ØD	ØAH7	L1	L2	Stroke C	Price each 1 to 4
CTH20-184/209	184-209	40	20	72	14	25	346,50 €
CTH20-240/270	240-270	40	20	82	19	30	346,50 €
CTH20-224/259	224-259	40	20	97	19	35	346,50 €
CTH20-260/313	260-313	40	20	95	19	53	346,50 €