


## Male mounting

## D-PARss D-KONss


- **Very high deformation allowing high** levels of energy to be absorbed.
- Progressive deformation
- Materials :  
Core : Stainless steel plates (A2)  
Head : Rubber
- **Hardness : NK 55-60 Shore A**
- Working temp: - 40°C to +70°C

### Uses

- Shock-absorbing stop
- D-KON12-80-30/SS square base 80x80mm

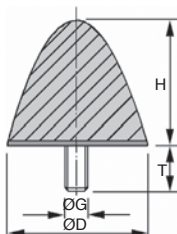

Type D-PARss

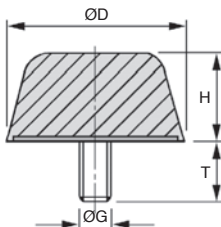

Type D-KONss

### DISCOUNTS

| Qty   | 1+   | 6+   | 20+  | 40+  | 100+       |
|-------|------|------|------|------|------------|
| Disc. | List | -10% | -15% | -20% | On request |

| Part number       | ØG  | T  | ØD  | H  | Stock* | Price each<br>1 to 5 |
|-------------------|-----|----|-----|----|--------|----------------------|
| D-PAR6-20-24/SS   | M6  | 18 | 20  | 24 | ✓      | 3,78 €               |
| D-PAR8-30-36/SS   | M8  | 20 | 30  | 36 | ✓      | 5,85 €               |
| D-PAR8-35-40/SS   | M8  | 20 | 35  | 40 | ✓      | 15,84 €              |
| D-PAR8-50-67/SS   | M8  | 36 | 50  | 67 | ✓      | 16,27 €              |
| D-PAR10-50-58/SS  | M10 | 28 | 50  | 58 | ✓      | 12,63 €              |
| D-KON6-25-17/SS   | M6  | 18 | 25  | 17 | ✓      | 3,62 €               |
| D-KON10-50-18/SS  | M10 | 28 | 50  | 18 | ✓      | 9,09 €               |
| D-KON12-80-30/SS  | M12 | 35 | 80  | 30 | -      | 48,56 €              |
| D-KON16-125-45/SS | M16 | 45 | 125 | 45 | -      | 105,56 €             |

\*Depending on availability - Dimensions in mm