

# Idler for plate chain



## DBL820 For chain ranges 820 and 815

- For use with CAP820 and CAP815 plate chains

- Materials:



Low friction acetal  
Stainless steel screws

- Operating temp.: -40°C to +85°C  
(+70°C in humid environments)

- For dimensions and bore tolerances,  
please refer to technical pages

### Advantage

- Two part design facilitates easy assembly

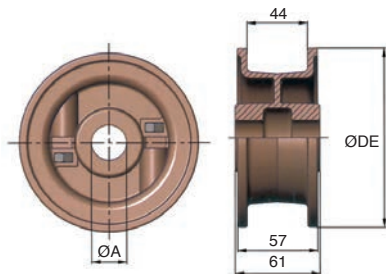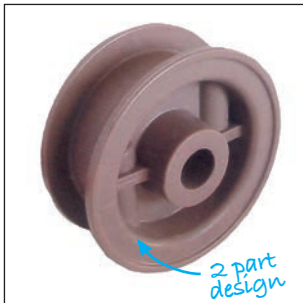

### DISCOUNTS

| Qty   | 1+   | 5+  | 10+        |
|-------|------|-----|------------|
| Disc. | List | -5% | On request |

| Part number  | ØDE | Bore<br>ØA | Weight<br>(kg) | Price each<br>1 to 4 |
|--------------|-----|------------|----------------|----------------------|
| DBL820-21-25 | 129 | 25         | 0,3            | 12,60 €              |
| DBL820-21-30 | 129 | 30         | 0,3            | 12,60 €              |
| DBL820-21-35 | 129 | 35         | 0,3            | 12,60 €              |
| DBL820-21-40 | 129 | 40         | 0,3            | 12,60 €              |
| DBL820-23-25 | 141 | 25         | 0,4            | 14,13 €              |
| DBL820-23-30 | 141 | 30         | 0,4            | 14,13 €              |
| DBL820-23-35 | 141 | 35         | 0,4            | 14,13 €              |
| DBL820-23-40 | 141 | 40         | 0,4            | 14,55 €              |
| DBL820-25-25 | 153 | 45         | 0,4            | 14,41 €              |
| DBL820-25-30 | 153 | 30         | 0,4            | 14,41 €              |
| DBL820-25-35 | 153 | 35         | 0,4            | 14,41 €              |
| DBL820-25-40 | 153 | 40         | 0,4            | 14,41 €              |

Dimensions in mm