


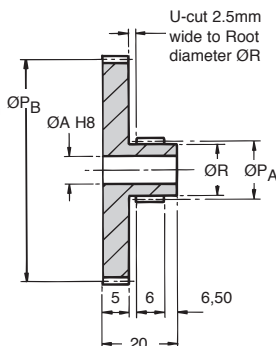

- Pressure angle 20°
- Material:
Steel 20NCD2
- U shaped groove between the two sets of teeth

Options

- Alternative number of teeth
- Alternative materials (stainless steel, brass..)
- Alternative modules (>3)



DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z _A Teeth	PCD ØP _A	Z _B Teeth	PCD ØP _B	Bore ØA	ØFoot ØR	Price each 1 to 5
DG0.5-16/48	16	8,50	48	24,00	4,00	6,45	48,21 €
DG0.5-24/60	24	12,00	60	30,00	6,00	10,45	48,81 €
Gears available up to this size							
DG0.5-24/144	24	12,00	144	72,00	6,00	10,45	53,00 €

Dimensions in mm