


- Pressure angle 20°
- Material: Steel 20NCD2
- U shaped groove between the two sets of teeth

Options

- Alternative number of teeth
- Alternative materials (stainless steel, brass..)
- Alternative modules (>3)

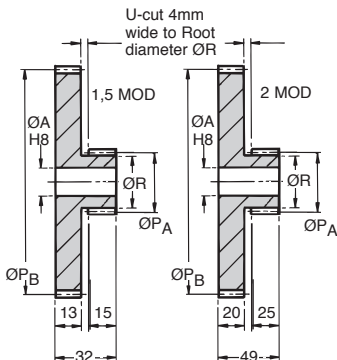

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Module	Z _A Teeth	PCD ØP _A	Z _B Teeth	PCD ØP _B	Bore ØA	ØFoot ØR	Price each 1 to 5
DG1.5-16/48	1,5	16	24,00	48	72,00	10	13,00	108,12 €
DG1.5-20/100		20	30,00	100	150,00	10	19,00	227,27 €
		Gears available up to this size						↓
DG1.5-20/120	2	20	30,00	120	180,00	10	19,00	359,48 €
DG2-15/45		15	30,00	45	90,00	15	24,00	153,92 €
DG2-15/60		15	30,00	60	120,00	15	24,00	279,48 €
		Gears available up to this size						↓
DG2-20/120		20	40,00	120	240,00	15	34,00	657,11 €

Dimensions in mm