



Motor-gearbox 12V and 24V DC



Torque from 1.5Nm to 2Nm

DOG316

- Gearbox type: worm
- Bearings: self-lubricating bushes
- Working temp.: -40°C to +80°C
- Weight: 1kg
- Ingress protection: IP40
- Angular backlash: N/A
- Max axial load: N/A
- Radial load: N/A

Accessories

- Servo Amplifiers **FIRSTDC-1Q-60/10** and **NANODC- 1Q-30/3**
- Power Supplies **ALIDR30-12**, **ALIDR60-24**, **ALIDR-120-24**

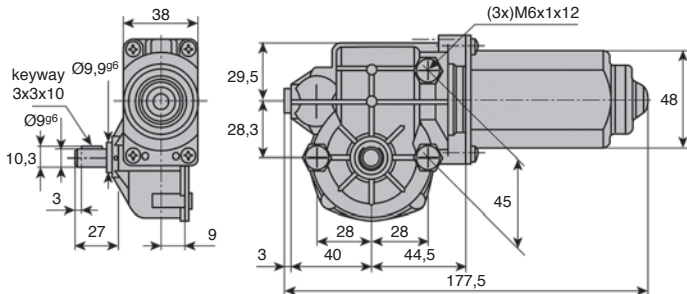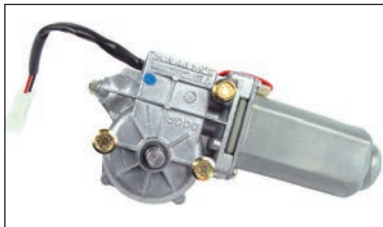

DISCOUNTS

Qty	1+	6+	10+
Disc.	List	-7%	On request

Part number	Ratios	Rendement	Loaded speed (rpm)	Nominal torque (Nm)	Nominal current (A)	Consistent card		Price each 1 to 5
12V DC Version								
DOG316-12-46	62:1	0,5	38	2,0	3,4	No	Yes	116,08 €
DOG316-12-30	62:1	0,5	32	1,5	3,0	No	Yes	116,08 €
24V DC Version								
DOG316-24-75	62:1	0,5	65	1,5	3,0	No	Yes	116,08 €
DOG316-24-46	62:1	0,5	38	2,0	1,7	Yes	Yes	116,08 €

Dimensions in mm