


MODULE 0.25

Stainless steel 303

- **Quality standard 9**
- Pressure angle 20°
- Material:
stainless steel (303) Z10CNF18.09
- Linear speed 300m/min

Torque and power indication				
For 50 teeth at 1000 rpm				
	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	fibre
Nm	0.050	0.230	0.024	0.019
kW	0.005	0.031	0.002	0.002

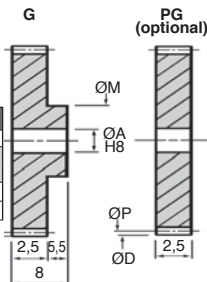

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Weight (kg)		Price each 1 to 5	
						G	PG	G	PG
G0.25-20	20	5,00	5,50	5,50	2	0,0004	0,0003	20,50 €	On request
G0.25-21	21	5,25	5,75	5,75	2	0,0004	0,0004	20,71 €	
G0.25-22	22	5,50	6,00	6,00	2	0,0005	0,0004	20,82 €	
G0.25-23	23	5,75	6,25	6,25	2	0,0005	0,0004	25,98 €	
G0.25-24	24	6,00	6,50	6,50	2	0,0005	0,0005	21,21 €	
G0.25-25	25	6,25	6,75	6,75	2	0,0006	0,0005	26,48 €	
G0.25-26	26	6,50	7,00	7,00	2	0,0006	0,0006	21,53 €	
G0.25-27	27	6,75	7,25	7,25	2	0,0007	0,0006	26,86 €	
G0.25-28	28	7,00	7,50	7,50	2	0,0007	0,0007	27,01 €	
G0.25-29	29	7,25	7,75	7,75	2	0,0008	0,0007	27,29 €	
G0.25-30	30	7,50	8,00	8,00	3	0,0008	0,0007	27,54 €	
G0.25-31	31	7,75	8,25	8,00	3	0,0009	0,0008	27,71 €	
G0.25-32	32	8,00	8,50	8,00	3	0,0010	0,0008	27,92 €	
G0.25-33	33	8,25	8,75	8,00	3	0,0010	0,0009	28,19 €	
G0.25-34	34	8,50	9,00	8,00	3	0,0011	0,0010	28,41 €	
G0.25-35	35	8,75	9,25	8,00	3	0,0012	0,0010	28,70 €	
G0.25-36	36	9,00	9,50	8,00	3	0,0012	0,0011	28,95 €	
G0.25-37	37	9,25	9,75	8,00	3	0,0013	0,0012	29,17 €	
G0.25-38	38	9,50	10,00	8,00	3	0,0014	0,0012	23,79 €	
G0.25-39	39	9,75	10,25	8,00	3	0,0014	0,0013	23,93 €	
G0.25-40	40	10,00	10,50	8,00	3	0,0015	0,0014	24,13 €	
G0.25-41	41	10,25	10,75	8,00	3	0,0016	0,0014	30,04 €	
G0.25-42	42	10,50	11,00	8,00	3	0,0017	0,0015	30,30 €	

Dimensions in mm

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Weight (kg)		Price each 1 to 5	
						G	PG	G	PG
G0.25-43	43	10,75	11,25	8,00	3	0,0017	0,0016	30,48 €	
G0.25-44	44	11,00	11,50	8,00	3	0,0018	0,0017	30,67 €	
G0.25-45	45	11,25	11,75	8,00	3	0,0019	0,0018	30,88 €	
G0.25-46	46	11,50	12,00	8,00	3	0,0020	0,0019	31,13 €	
G0.25-47	47	11,75	12,25	8,00	3	0,0021	0,0019	31,37 €	
G0.25-48	48	12,00	12,50	10,00	3	0,0022	0,0020	31,57 €	
G0.25-49	49	12,25	12,75	10,00	3	0,0023	0,0021	31,79 €	
G0.25-50	50	12,50	13,00	10,00	3	0,0023	0,0022	32,00 €	
G0.25-52	52	13,00	13,50	10,00	3	0,0025	0,0024	32,16 €	
G0.25-55	55	13,75	14,25	10,00	3	0,0028	0,0027	26,58 €	
G0.25-60	60	15,00	15,50	12,00	4	0,0034	0,0031	33,53 €	
G0.25-62	62	15,50	16,00	12,00	4	0,0036	0,0034	33,76 €	
G0.25-63	63	15,75	16,25	12,00	4	0,0037	0,0035	33,93 €	
G0.25-64	64	16,00	16,50	12,00	4	0,0038	0,0036	34,27 €	
G0.25-65	65	16,25	16,75	12,00	4	0,0040	0,0037	34,63 €	
G0.25-68	68	17,00	17,50	12,00	4	0,0043	0,0041	28,23 €	
G0.25-70	70	17,50	18,00	12,00	4	0,0046	0,0044	28,41 €	
G0.25-72	72	18,00	18,50	12,00	4	0,0049	0,0046	35,52 €	
G0.25-75	75	18,75	19,25	12,00	4	0,0053	0,0050	35,76 €	
G0.25-76	76	19,00	19,50	12,00	4	0,0054	0,0052	36,13 €	
G0.25-80	80	20,00	20,50	12,00	4	0,0060	0,0058	36,48 €	
G0.25-84	84	21,00	21,50	12,00	4	0,0066	0,0064	29,63 €	
G0.25-86	86	21,50	22,00	12,00	4	0,0069	0,0067	29,75 €	
G0.25-88	88	22,00	22,50	12,00	4	0,0073	0,0070	36,97 €	
G0.25-90	90	22,50	23,00	12,00	4	0,0076	0,0074	37,07 €	
G0.25-93	93	23,25	23,75	12,00	4	0,0081	0,0079	37,28 €	
G0.25-95	95	23,75	24,25	12,00	4	0,0085	0,0082	37,61 €	
G0.25-96	96	24,00	24,50	12,00	4	0,0087	0,0084	37,75 €	
G0.25-97	97	24,25	24,75	12,00	4	0,0088	0,0086	37,92 €	
G0.25-99	99	24,75	25,25	12,00	4	0,0092	0,0090	38,07 €	
G0.25-100	100	25,00	25,50	12,00	4	0,0094	0,0092	38,29 €	
G0.25-108	108	27,00	27,50	12,00	4	0,0110	0,0107	38,58 €	
G0.25-110	110	27,50	28,00	12,00	4	0,0114	0,0111	38,82 €	
G0.25-115	115	28,75	29,25	12,00	4	0,0124	0,0122	39,20 €	
G0.25-120	120	30,00	30,50	12,00	4	0,0135	0,0133	39,86 €	
G0.25-124	124	31,00	31,50	12,00	4	0,0144	0,0142	40,43 €	
G0.25-127	127	31,75	32,25	12,00	4	0,0151	0,0149	40,95 €	
G0.25-130	130	32,50	33,00	12,00	4	0,0159	0,0156	41,59 €	
G0.25-132	132	33,00	33,50	12,00	4	0,0164	0,0161	42,36 €	
G0.25-136	136	34,00	34,50	12,00	4	0,0174	0,0171	44,27 €	
G0.25-140	140	35,00	35,50	12,00	4	0,0184	0,0182	46,09 €	
G0.25-148	148	37,00	37,50	12,00	4	0,0206	0,0203	49,18 €	
G0.25-150	150	37,50	38,00	12,00	4	0,0211	0,0209	53,66 €	
G0.25-156	156	39,00	39,50	12,00	4	0,0229	0,0226	57,44 €	
G0.25-180	180	45,00	45,50	12,00	4	0,0304	0,0302	49,71 €	
G0.25-200	200	50,00	50,50	12,00	4	0,0376	0,0373	72,07 €	
G0.25-250	250	62,50	63,00	20,00	6	0,0587	0,0585	62,88 €	
↓ Gears available up to this size ↓									
G0.25-558	558	139,50	140,00	Dimensions: contact us				On request	

On request