

GA6 GA8

Fixed force, 50 to 400N


- Gas spring
- Works in compression (push) mode
- Operating fluid: Gas (Nitrogen) and oil
- Materials:
 - Rod: Chrome-plated steel
 - Body: Steel
 - Rod end: Nylon
- Spring must be mounted with piston pointing down
- Size 6: from 50N to 400N
- Size 8: from 100N to 540N



Supplied with nylon end

Uses

- Opening of bonnets or boots
- Saves effort

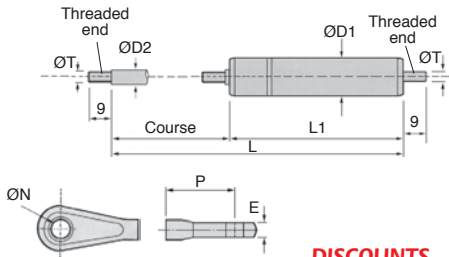

DISCOUNTS

Qty	1+	6+	10+	15+	20+
Disc.	List	-10%	-15%	-20%	On request

Part number	Stroke (mm)	L (mm)	L1 (mm)	ØD1 (mm)	ØD2 (mm)	ØT (mm)	ØN (mm)	P (mm)	E (mm)	Oil zone length (mm)	Force (N)	Stock*	Price each 1 to 5
Size 6													
GA6060050	60	160	100	15	6	M5	6	17	8	20	50	✓	115,52 €
GA6100080	100	240	140	15	6	M5	6	17	8	20	80	✓	116,20 €
GA6150100	150	340	190	15	6	M5	6	17	8	20	100	✓	116,20 €
GA6200200	200	440	240	15	6	M5	6	17	8	20	200	-	119,06 €
Size 8													
GA8100100	100	264	164	18	8	M6	8	21	10	30	100	✓	126,43 €
GA8150200	150	364	214	18	8	M6	8	21	10	30	200	✓	128,31 €
GA8200300	200	464	264	18	8	M6	8	21	10	30	300	✓	130,55 €
GA8250400	250	564	314	18	8	M6	8	21	10	30	400	✓	132,48 €

*Depending on availability - Dimensions in mm