

Recommended in absence of seal

GP22
GP23

- **Wide positioning tolerances**
- Very adaptable
- Suitable for vibrations
- Materials:

White zinc steel or stainless steel 303

Assembly


- When used with **AC122** hook, dimension $X = 87\text{mm}$ to withstand a tension of 350N
- Dimension X taken on the first hole of the hook.

Info

- **Not sold individually, please contact us for details**

Accessory

- Hooks **AC122** (t.imagetome1 p.125)

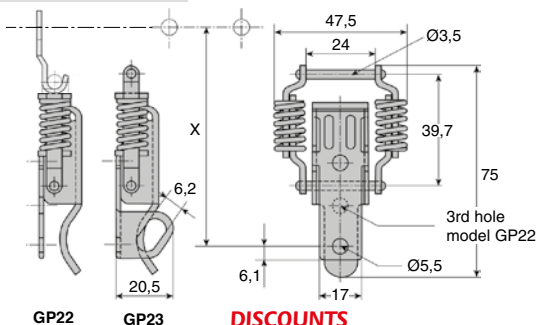

DISCOUNTS

Qty	1+	51+	101+	250+	400+	500+
Disc.	List	-10%	-15%	-20%	-25%	On request

Part number	Material	Wire Ø	Lever thickness	Back-plate thickness	Max. tension (N)	Weight (g)	Price each 1 to 50
With padlock holder							
GP22-ZB	Steel	1,7	20/10th	25/10th	450	75	7,58 €
GP22-SS	Stainless steel	2,7	20/10th	25/10th	450	75	15,64 €
Without padlock holder							
GP23-ZB	Steel	2,5	20/10th	25/10th	450	75	7,80 €
GP23-SS	Stainless steel	3,5	20/10th	25/10th	450	75	16,11 €

*Subject to availability - Dimensions in mm