

Manual locking clamp



HK

For **IKO**® LWL guide rail

- For IKO LWL7 to LWL15 rails
- Simple, solid construction
- Contact surfaces held in floating position
- Precise positioning
- Gripping force up to 180N

Applications

- Pick and place machines
- Measuring systems
- Mounting accessories




Operating principle

- Tightening screw

Info.

- This product is not available for LWL5 and LWL20 rails
- Dimension C must be respected
- ① Adaptor plate (to do by yourself)

Sizes in stock

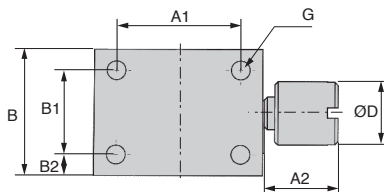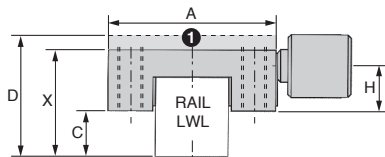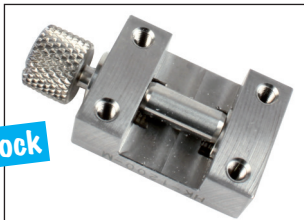

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-10%	On request

Part number	For rail	Holding force (N)	Tightening torque (Nm)	A	A1	A2	B	B1	B2	C	X	G	ØD	H	Price each
HK0700M	LWL7	65	0,15	17	12	7	12	8	2	2,0	8	M2	6	4,30	193,58 €
HK0900M	LWL9	100	0,24	20	15	9	17	11	3	2,7	10	M3	8	5,35	251,36 €
HK1200M	LWL12	150	0,50	27	20	10	19	13	3	3,5	13	M3	10	7,15	265,33 €
HK1500M	LWL15	180	1,02	32	25	14	20	14	3	5,0	16	M3	12	8,05	277,55 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel



Manual locking clamp

For **IKO**® LWH guide rail

HK

- For IKO LWH15 to LWH45 rails
- Simple, solid construction
- Contact surfaces held in floating position
- Precise positioning
- Gripping force up to 2000N

Applications

- Pick and place machines
- Measuring systems
- Mounting accessories





Operating principle

- With indexing handle

Info.

- Attention : Dimension C must be respected
- Adaptor plate (optional accessory)
- X Operating height
- ① D Mounting height of linear rail (Inc adaptor plate if applicable)

Sizes in stock

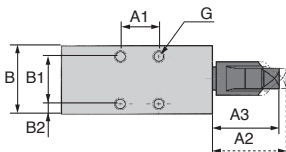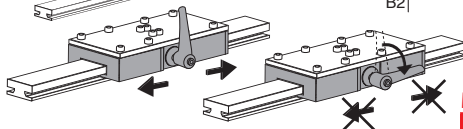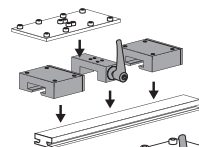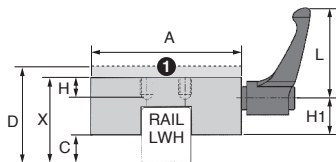

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-10%	On request

Part number	For rail	Holding force (N)	(Nm)	A	A1	A2	A3	B	B1	B2	C	X	G	L	H	H1	Price each
HK1501A	LWH15	1200	5	47	17	33,5	30,5	25	17	4,0	6,5	24	M4	44	5	12,5	184,67 €
HK2001A	LWH20	1200	7	60	15	41,5	38,5	24	15	4,5	10	30	M5	63	6	13,0	194,62 €
HK2501A	LWH25	1200	7	70	20	41,5	38,5	30	20	5,0	12	36	M6	63	8	15,0	200,73 €
HK3001A	LWH30	2000	15	90	22	50,5	46,5	39	22	8,5	12	42	M6	78	8	21,5	209,80 €
HK3501A	LWH35	2000	15	100	24	50,5	46,5	39	24	7,5	16	48	M8	78	10	21,5	215,94 €
HK4501A	LWH45	2000	15	120	26	50,5	46,5	44	26	9,0	18	60	M10	78	14	26,5	235,65 €

Dimensions in mm

Manual locking clamp



HK

For IKO® LRX rail

- For IKO LRX15-LRX45 rails
- Simple, solid construction
- Contact surfaces held in floating position
- Precise positioning
- Gripping force up to 2000N

Applications



- Pick and place machines
- Measuring systems
- Mounting accessories

Operating principle

- With indexing handle

Info.

- Attention : Dimension C must be respected
- ① Adaptor plate (optional accessory)
- X Operating height
- D Mounting height of linear rail (inc adaptor plate if applicable)
- Product not suitable for LRX25 or LRX30 rails

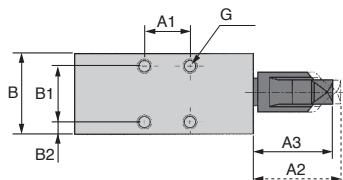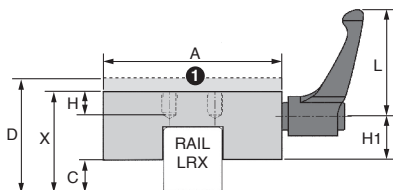

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-10%	On request

Part number	For rail	Holding force (N)	(Nm)	A	A1	A2	A3	B	B1	B2	C	X	G	L	H	H1	Price each
HK1510B	LRX15	1200	7	47	38	33,5	30,5	29	20	4,5	6,5	24	M5	44	6	13,4	229,18 €
HK2010B	LRX20	1200	5	60	15	33,5	30,5	24	15	4,5	7	30	M5	44	6	17,5	250,84 €
HK3501A	LRX35	2000	15	100	24	50,5	46,5	39	24	7,5	16	48	M8	78	10	21,5	215,94 €
HK4501A	LRX45	2000	15	120	26	50,5	46,5	44	26	9	18	60	M10	78	14	26,5	235,65 €

Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tél: 0 825 88 5000 Service 0,15 €/min + prix appel



Manual locking clamp

For Drylin® T guide rail

HK

- For Drylin® T TS-01-15 to TS-01-30 rails

- Gripping force up to 500N

- With indexing handle

Advantages

- Simple, solid construction

- Contact surfaces held in floating position

- Precise positioning



Applications

- Pick and place machines

- Measuring systems

- Mounting accessories

Sizes in stock

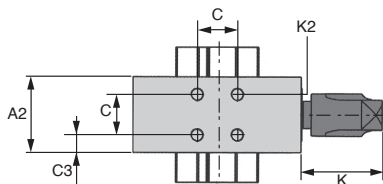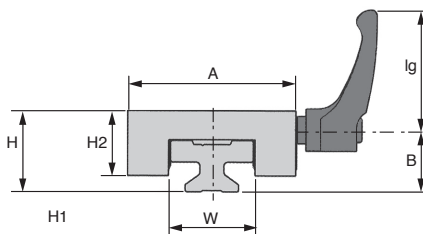

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-10%	On request

Part number	rail	A	W	A2	H	H2	For K	K2	C	C3	lg	B	Price each
HK1511A	TS01-15	47	22	23	24	20,0	30	M4x5	15	4,0	44,00	18,9	195,73 €
HK2011A	TS01-20	63	31	28	30	24,0	30	M5x6	15	6,5	44,00	23,0	211,17 €
HK2511A	TS01-25	70	34	35	36	31,0	39	M6x8	20	7,5	63,63	26,2	212,90 €
HK3011A	TS01-30	90	40	38	42	35,5	47	M6x8	20	9,0	78,00	32,4	218,50 €

Dimensions in mm