
 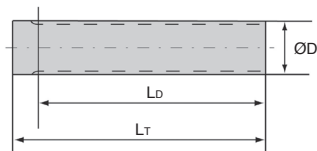


- Bar stock to be cut to length by the customer
- The overall length is the same as the maximum length
- Material : Steel C40

Info.

- We are unable to modify this product



DISCOUNTS

Qty	1+	2+	4+
Disc.	List -20%	List -20%	On request

Part number	Z Teeth	ØD External	Length of teeth L _D	Total length L _T	Price each
18HTD8M-BAR	18	44,47	200	200	47,27 €
19HTD8M-BAR	19	47,01	200	200	50,51 €
20HTD8M-BAR	20	49,56	200	200	53,27 €
21HTD8M-BAR	21	52,11	200	200	55,44 €
22HTD8M-BAR	22	54,65	200	200	58,15 €
23HTD8M-BAR	23	57,20	200	200	60,87 €
24HTD8M-BAR	24	59,75	200	200	63,57 €
25HTD8M-BAR	25	62,29	200	200	65,19 €
26HTD8M-BAR	26	64,84	200	200	70,67 €
28HTD8M-BAR	28	69,93	200	200	77,74 €
30HTD8M-BAR	30	75,03	200	200	88,57 €
32HTD8M-BAR	32	80,12	200	200	102,85 €
34HTD8M-BAR	34	85,21	200	200	111,97 €
35HTD8M-BAR	35	87,76	200	200	124,06 €
36HTD8M-BAR	36	90,30	200	200	130,12 €
38HTD8M-BAR	38	95,40	200	200	145,30 €
40HTD8M-BAR	40	100,49	200	200	159,15 €
44HTD8M-BAR	44	110,67	200	200	188,85 €
48HTD8M-BAR	48	120,86	200	200	220,95 €

Dimensions in mm