


180° ball and socket joint steel or stainless steel

IBJ Steel/steel or stainless steel/stainless steel contact IBJss

- **Inline ball and socket joint similar to DIN 71802**
- Body to DIN 71805
- Stem to DIN 71803
- **Materials:**
 - Zinc plated steel
 - Stainless steel 1.4305 (A2 stainless steel)



**steel or
stainless steel**

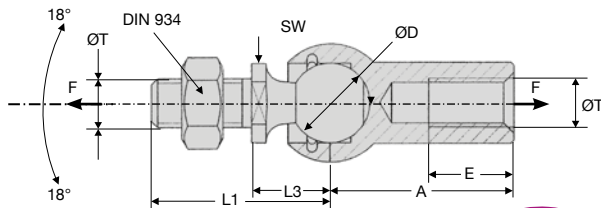

**NEW
DISCOUNTS**

DISCOUNTS A / steel

Qty	1+	6+	20+	40+	60+
Disc.	Price	-20%	-30%	-50%	On request

DISCOUNTS B / stainless steel

Qty	1+	6+	20+	40+	60+
Disc.	Price	-15%	-20%	-30%	On request

Part number	ØD	ØT	A	L1	L3	E	SW	Axial load F (N)	Weight (kg)	Price each 1 to 5
Steel										
IBJ-5	8	M5	22	19,2	9	10,2	7	30	0,015	✓ A 5,35 €
IBJ-6	10	M6	25	23,5	11	11,5	8	40	0,025	✓ A 6,86 €
IBJ-8	13	M8	30	29,5	13	14,0	11	60	0,053	✓ A 7,25 €
IBJ-10	16	M10	35	36,0	16	15,5	13	80	0,104	✓ A 10,05 €
IBJ-14x1,5	19	M14x1,5	45	48,0	20	21,5	16	100	0,221	✓ A 25,66 €
Stainless Steel										
IBJ-5/SS	8	M5	22	19,2	9	10,2	7	30	0,015	✓ B 9,64 €
IBJ-6/SS	10	M6	25	23,5	11	11,5	8	40	0,025	✓ B 11,55 €
IBJ-8/SS	13	M8	30	29,5	13	14,0	11	60	0,055	✓ B 12,68 €
IBJ-10/SS	16	M10	35	36,0	16	15,5	13	80	0,105	- B 20,76 €

*Depending on availability - Dimensions in mm