

Economy range

KBww
KBSww

- Precise guiding accuracy
- Integrated seals
- Working temperature range -20°C to +80°C
- Material:


Housing: Steel or stainless steel

Ball raceway: Polyamide

info.

- Should be used with Z-A or Z-B hardened and ground shafts

Economy range

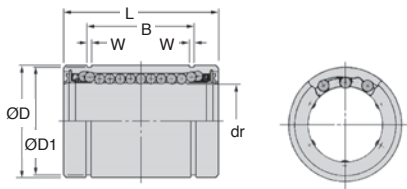

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-30%	On request

Part number	dr	ØD	L	B	W	D1	Loads		Stock ^k	Price each 1 to 4
							Dynamic C (N)	Static Co (N)		
Steel with polyamide raceway										
KB-8-WW	8 ⁰ _{+0,008}	16 ⁰ _{+0,008}	25 ⁰ _{+0,2}	16,5 ⁰ _{+0,2}	1,10	15,2	265	402	✓	9,17 €
KB-12-WW	12 ⁰ _{+0,008}	22 ⁰ _{+0,009}	32 ⁰ _{+0,2}	22,9 ⁰ _{+0,2}	1,30	21,0	510	784	✓	10,70 €
KB-16-WW	16 ^{-0,001} _{+0,009}	26 ⁰ _{+0,009}	36 ⁰ _{+0,2}	24,9 ⁰ _{+0,2}	1,30	24,9	578	892	✓	12,09 €
KB-20-WW	20 ^{-0,001} _{+0,009}	32 ⁰ _{+0,011}	45 ⁰ _{+0,2}	31,5 ⁰ _{+0,2}	1,60	30,3	862	1370	✓	12,74 €
KB-25-WW	25 ^{-0,001} _{+0,011}	40 ⁰ _{+0,011}	58 ⁰ _{+0,3}	44,1 ⁰ _{+0,3}	1,85	37,5	980	1570	✓	22,29 €
KB-30-WW	30 ^{-0,001} _{+0,011}	47 ⁰ _{+0,011}	68 ⁰ _{+0,3}	52,1 ⁰ _{+0,3}	1,85	44,5	1570	2740	✓	25,77 €
KB-40-WW	40 ^{-0,002} _{+0,013}	62 ⁰ _{+0,013}	80 ⁰ _{+0,3}	60,6 ⁰ _{+0,3}	2,15	59,0	2160	4020	✓	44,19 €
Stainless steel with polyamide raceway										
KBS-12-WW	12 ⁰ _{+0,008}	22 ⁰ _{+0,009}	32 ⁰ _{+0,2}	22,9 ⁰ _{+0,2}	1,30	21,00	510	784	✓	29,16 €
KBS-16-WW	16 ^{-0,001} _{+0,009}	26 ⁰ _{+0,009}	36 ⁰ _{+0,2}	24,9 ⁰ _{+0,2}	1,30	24,90	578	892	✓	40,83 €
KBS-20-WW	20 ^{-0,001} _{+0,009}	32 ⁰ _{+0,011}	45 ⁰ _{+0,2}	31,5 ⁰ _{+0,2}	1,60	30,30	862	1370	✓	47,87 €
KBS-25-WW	25 ^{-0,001} _{+0,011}	40 ⁰ _{+0,011}	58 ⁰ _{+0,3}	44,1 ⁰ _{+0,3}	1,85	37,50	980	1570	✓	70,06 €
KBS-30-WW	30 ^{-0,001} _{+0,011}	47 ⁰ _{+0,011}	68 ⁰ _{+0,3}	52,1 ⁰ _{+0,3}	1,85	44,50	1570	2740	-	93,44 €
KBS-40-WW	40 ^{-0,002} _{+0,013}	62 ⁰ _{+0,013}	80 ⁰ _{+0,3}	60,6 ⁰ _{+0,3}	2,15	59,00	2160	4020	-	151,83 €

*Depending on availability - Dimensions in mm