

Friction torque limiter



LC

Max torque 30Nm to 240Nm

Adjustable clutch

- Place the wheel (gear, pulley, chain sprocket) between the two friction disks and tighten/loosen the thread to achieve the torque setting required.
- Supplied with 2 spring washers
- Only one can be fitted for lower transmissible torque
- Supplied pre-bored

Material:

Steel

Friction disks do not contain asbestos





LC 40-50

Option

- Bore and keyway to your specifications
(Mini order quantity: 30)

Info.

- Friction disks should never come into contact with oil as this could cause damage or affect the performance
- **Sprocket not supplied**

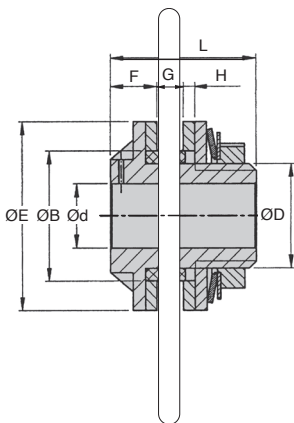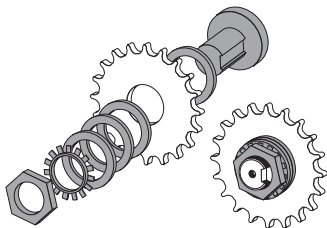

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	OE	ØBh8	Ød	F	G max	H	ØD	L	N° springs	torque max (Nm)	Recommended sprocket Pitch	N° of teeth	Stock	Price each
LC40-2-7	40	26	7	9	6	3	22	30,0	1	15	3/8"	18-21	-	29,31 €
									2	28	1/2"	15		
LC50-2-7	50	35	7	10	6	3	32	35,5	1	30	3/8"	19-23	✓	32,58 €
									2	55	1/2"	17		

*Depending on availability - Dimensions in mm

HPC

WEB
04/2020

www.hpceurope.com

Tel. +33(0)4 37 496 496



Friction torque limiter

Max torque 190Nm to 1.800Nm

LC

- Adjustable clutch

- Place the wheel (gear, pulley, chain sprocket) between the two friction disks and tighten/loosen the thread to achieve the torque setting required.
- Supplied with 2 spring washers
- Only one can be fitted for lower transmissible torque
- Supplied pre-bored
- Material:
Steel
- Friction disks do not contain asbestos





LC 65-85-95-120-140-170

Option

- Bore and keyway to your specifications (Mini order quantity: 30)

Info.

 - Friction disks should never come into contact with oil as this could cause damage or affect the performance
- **Sprocket not supplied**

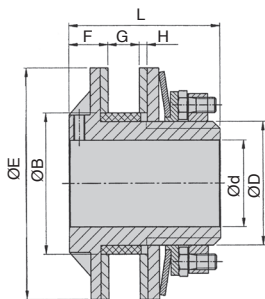

LC 65-85-95-120-140-170

DISCOUNTS

Qty	1+	2+	5+
Disc.	List	-5%	On request

Part number	OE	OBh	Od	F	G max	H	OD	L	N° springs	torque max (Nm)	Recommended sprocket Pitch	N° of teeth	Stock*	Price each
LC65-2-10	65	45	10	16	9	4	36	53	1	70	3/8"	27	✓	47,17 €
								55	2	120	1/2"	21		
LC85-2-15	85	52	15	16	11	4	45	59	1	130	3/8"	38	✓	59,26 €
								61	2	240	1/2"	25		
LC95-2-15	95	60	15	17	11	4	52	67	1	190	1/2"	30	-	88,49 €
								78	2	340	3/4"	19		
LC120-2-20	120	73	20	19	16	4	64	78	1	350	1/2"	38	✓	105,00 €
								94	2	650	3/4"	25		
LC140-2-20	140	90	20	22	17	4	85	86,5	1	650	3/4"	35	-	174,03 €
								94	2	1200	1"	21		
LC170-2-28	170	100	28	25,5	18,5	4,5	90	94	1	1000	3/4"	35	-	206,98 €
								94	2	1800	1 1/4"	22		

*Depending on availability - Dimensions in mm