



# DryLin® N miniature guiding system

Load up to 1000N

NK80  
NW80

Small but  
effective

- Linear rail with polymer slide
- Reduced size (both height and surface)
- Dry working, no maintenance required
- Not affected by dust
- Corrosion-resistant
- Reduced coefficient of friction means wear is reduced
- Reduced weight thanks to use of a combination of aluminium and plastic
- Very high speeds and acceleration possible
- Replaceable sliding parts in iglidur® J
- Materials:



Slide body: Plastic

Rails: Anodised aluminium

- Symmetrical hole pattern, C5=C6

## Options

- Rail length up to 3960mm max.

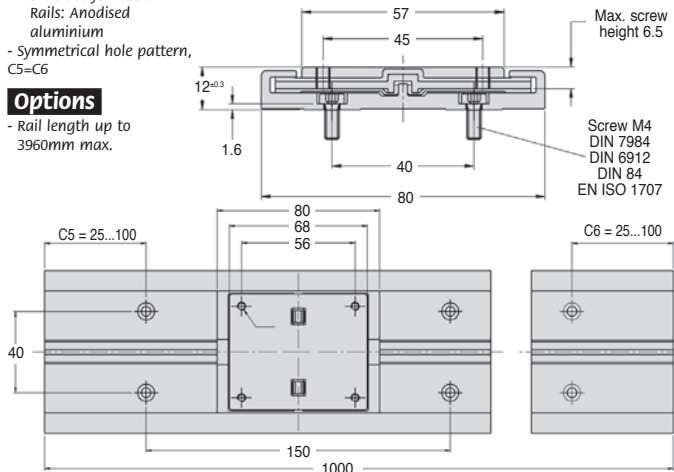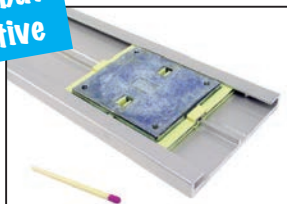

## DISCOUNTS

Qty	1+	5+	10+
Disc.	List	-6%	On request

Part number	Type	Weight (g)	Stock*	Price each 1 to 4
NK02-80-1000	1 Rail (1000mm) + 1 slide	1240	✓	106,74 €
NW02-80	1 slide only	100	✓	14,12 €

\*Depending on availability - Dimensions in mm