

Housing for open linear bearing

NSO For KB-OP and TK-OP bearings



- Open housing for open bearing
- Bearing not supplied
- Material:
Aluminium
- Circlips used for assembly

Options

- Compatible with **KB-OP** and **TK-OP** ranges

Advantages

- Use with long supported shafts to avoid flexing.

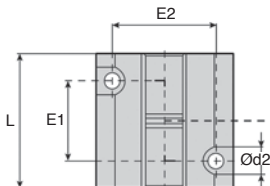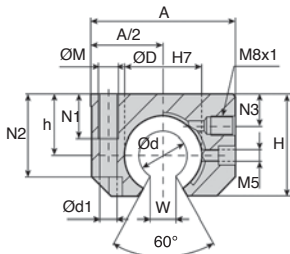

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	For shaft Ød	ØD	H	h	A	L	E1	E2	N1
NSO12	12	22	28	18	43	39	23	32	11
NSO16	16	26	35	22	53	43	26	40	13
NSO20	20	32	42	25	60	54	32	45	18
NSO25	25	40	51	30	78	67	40	60	22
NSO30	30	47	60	35	87	79	45	68	22
NSO40	40	62	77	45	108	91	58	86	26

Part number	N2	N3	Ød1	Ød2	ØM	W	Masse (g)	Stock*	Price each 1 to 4
NSO12	23,5	8	4,2	8	M5	7,0	110	✓	58,38 €
NSO16	30,0	12	5,2	10	M6	9,4	170	✓	60,45 €
NSO20	34,0	13	6,8	11	M8	10,2	300	✓	66,72 €
NSO25	40,0	15	8,6	15	M10	12,5	570	✓	80,26 €
NSO30	48,0	16	8,6	15	M10	13,9	860	✓	94,89 €
NSO40	60,0	20	10,3	18	M12	18,0	1600	✓	159,57 €

*Depending on availability - Dimensions in mm