



# Articulated foot with sheet metal base Ø80

Max load: 10,000N  
Rubber sole in EPDM, blue

PAMF80


- Articulated adjustable levelling feet
- Axial articulation +/- 10°
- With non-slip sole in EPDM Blue
- Stainless steel in shiny finish
- Materials:
  - Base: shiny 304 stainless steel sheet
  - Thread: 304 stainless steel, supplied without nut
  - Sole: EPDM blue

## Options


- Other thread dimensions on request
- 316 grade Stainless steel on request

## Advantages

- Hygienic special sole for easy cleaning.
- Food processing, Pharmaceutical and Chemical Environment

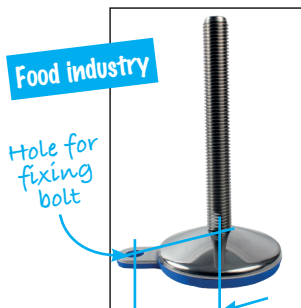

Large spacing allows use of a hammer drill

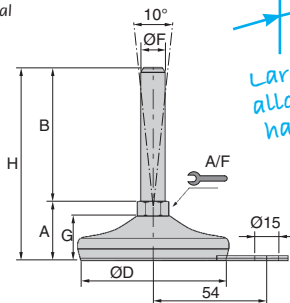

## DISCOUNTS

| Qty   | 1+    | 6+  | 10+  | 15+  | 20+        |
|-------|-------|-----|------|------|------------|
| Disc. | Price | -5% | -10% | -15% | On request |

| References          | ØD | ØF  | B   | A  | A/F | G  | H   | Static load(N) | Price per unit 1 to 5 |
|---------------------|----|-----|-----|----|-----|----|-----|----------------|-----------------------|
| PAMF80-12-100/SS/EB | 80 | M12 | 100 | 35 | 14  | 25 | 135 | 10000          | 29,62€                |
| PAMF80-12-150/SS/EB | 80 | M12 | 150 | 35 | 14  | 25 | 185 | 10000          | 31,76€                |
| PAMF80-16-100/SS/EB | 80 | M16 | 100 | 35 | 13  | 25 | 135 | 10000          | 31,76€                |
| PAMF80-16-150/SS/EB | 80 | M16 | 150 | 35 | 13  | 25 | 185 | 10000          | 33,84€                |
| PAMF80-20-100/SS/EB | 80 | M20 | 100 | 38 | 17  | 25 | 138 | 10000          | 35,47€                |
| PAMF80-20-150/SS/EB | 80 | M20 | 150 | 38 | 17  | 25 | 188 | 10000          | 38,07€                |
| PAMF80-20-200/SS/EB | 80 | M20 | 200 | 38 | 17  | 25 | 238 | 10000          | 42,04€                |

\*Within the limits of available stock - Dimensions in mm