

Fixed rubber levelling foot



PFC


Maximum load 3 150N

- Levelling support for small parts

- Materials:

Rod: steel or stainless steel 304

Base: NBR rubber hardness shore 70

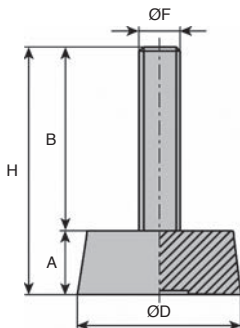

DISCOUNTS

| | | | |
|-------|------|-----|------------|
| Qty | 1+ | 50+ | 100+ |
| Disc. | List | -5% | On request |

| Part number | ØD | ØF | A | H | B | Max. load (N) | Stock* | Price each 1 to 49 |
|------------------------|----|-----|----|----|----|---------------|--------|--------------------|
| Steel | | | | | | | | |
| PFC40-8 | 40 | M8 | 16 | 41 | 25 | 1800 | ✓ | 3,24 € |
| PFC40-10 | 40 | M10 | 16 | 41 | 25 | 2250 | ✓ | 3,80 € |
| PFC40-12 | 40 | M12 | 16 | 41 | 25 | 3150 | ✓ | 4,39 € |
| Stainless steel | | | | | | | | |
| PFC40-8/SS | 40 | M8 | 16 | 41 | 25 | 1800 | ✓ | 3,80 € |
| PFC40-10/SS | 40 | M10 | 16 | 41 | 25 | 2250 | ✓ | 4,11 € |
| PFC40-12/SS | 40 | M12 | 16 | 41 | 25 | 3150 | ✓ | 5,60 € |

*Depending on availability - Dimensions in mm