


- **Levelling foot**
- Non slip base
- **Materials:**
 - Base: Black glass reinforced polyamide (Shore 70)
 - Spindle: Zinc plated steel or stainless 304 (nut not supplied)

Info.

- Values given for static loads will be reduced in case of a vibrating load

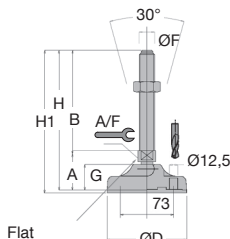

With non-slip base



DISCOUNTS

Qty	1+	20+	50+
Disc.	List -10%	On request	On request

Part number	ØD	Thread	ØF	B	A	A/F	G	H	H1	Static load (N)	Price each
											1 to 19
Steel spindle											
PR105-16-75	103	M16	75	51	20	32	126	129	25000	✓	17,76 €
PR105-16-150	103	M16	150	51	20	32	201	204	25000	✓	21,36 €
PR105-16-225	103	M16	225	51	20	32	276	279	25000	✓	26,31 €
PR105-20-125	103	M20	125	51	20	32	176	179	25000	✓	17,99 €
PR105-20-200	103	M20	200	51	20	32	251	254	25000	✓	21,34 €
PR105-20-250	103	M20	250	51	20	32	301	304	25000	✓	26,31 €
PR105-24-125	103	M24	125	51	20	32	176	179	25000	✓	17,99 €
PR105-24-200	103	M24	200	51	20	32	251	254	25000	✓	21,34 €
PR105-24-250	103	M24	250	51	20	32	301	304	25000	✓	26,31 €
Stainless steel spindle											
PR105-16-75/SS	103	M16	75	51	20	32	126	129	25000	✓	31,56 €
PR105-16-150/SS	103	M16	150	51	20	32	201	204	25000	✓	41,75 €
PR105-16-225/SS	103	M16	225	51	20	32	276	279	25000	✓	53,74 €
PR105-20-125/SS	103	M20	125	51	20	32	176	179	25000	✓	36,50 €
PR105-20-200/SS	103	M20	200	51	20	32	251	254	25000	✓	50,12 €
PR105-20-250/SS	103	M20	250	51	20	32	301	304	25000	✓	58,20 €
PR105-24-125/SS	103	M24	125	51	20	32	175	178	25000	-	36,50 €
PR105-24-200/SS	103	M24	200	51	20	32	250	253	25000	-	50,12 €
PR105-24-250/SS	103	M24	250	51	20	32	300	303	25000	-	58,20 €

*Depending on availability - Dimensions in mm