

Tensioner pulley

For V belts


PTGT

- Idler pulley

- Material:

PA6 reinforced with 30% fibreglass
steel bearing

- Max speed 5,000 RPM

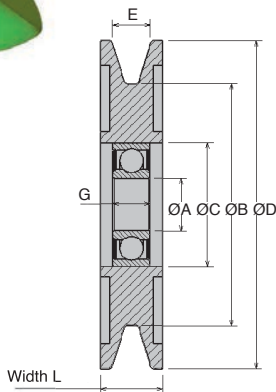

✓ INCREASED STOCK

DISCOUNTS

Qty	1+	10+	25+	50+
Disc.	List	-5%	-10%	On request

Part number	FOR round belt	ØD	Width L	ØB	Bearing	C	ØA	E	G	For shaft	Stock*	Price each 1 to 9
PTGR62-10-17	Ø10	76	18	62	6203 2ZZ	38	17	10,3	12	AXTR-M12	✓	17,50 €
PTGR89-14-17	Ø14	105	18	89	6203 2RS	38	17	14,3	12	AXTR-M12	✓	21,83 €
PTGR95-11-17	Ø11	114	20	95	6203 2RS	38	17	11,3	12	AXTR-M12	-	26,16 €

Dimensions en mm