

Radial bearing



Q6

3 versions available

- Radial contact ball bearing
- Single line of balls
- Static and dynamic loads are both radial loads

Versions

- Open: no protection
- ZZ: bearing with 2 shields
- 2RS: bearing with 2 seals

Info.

- ** Open
- 2 widths are displayed in the tables as bearings without seals are thinner




DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List	-10%	-15%	-20%	-30%	On request

Part number	Bore ØA	ØD	Width	Max. speed (rpm)	Dynamic load (N)	Static load (N)	Stock*		Price each 1 to 5		
							2RS	Open	ZZ	2RS	
Q693	3	8	3** / 4	60 000	560	179	-	14,70 €	8,22 €	On request	
Q624	4	13	5	40 000	1 300	485	✓	2,75 €	3,31 €	3,56 €	
Q634	4	16	5	36 000	1 730	670	-	10,51 €	4,22 €	12,07 €	
Q685	5	11	3** / 5	45 000	715	281	✓	14,36 €	7,56 €	11,22 €	
Q625	5	16	5	36 000	1 730	670	✓	3,31 €	2,75 €	3,31 €	
Q686	6	13	3,5** / 5	40 000	1 080	440	✓	10,60 €	On request		6,06 €
Q626	6	19	6	32 000	2 340	885	✓	3,16 €	2,89 €	2,49 €	
Q608	8	22	7	34 000	3 300	1 370	✓	2,36 €	3,98 €	2,36 €	
Q61800	10	19	5	24 000	1 720	840	✓	3,56 €	4,09 €	4,22 €	
Q6000	10	26	8	22 000	4 550	1 970	✓	3,42 €	3,56 €	3,70 €	
Q6200	10	30	9	18 000	5 100	2 390	✓	2,49 €	4,09 €	4,09 €	
Q6300	10	35	11	17 000	8 100	3 450	✓	7,44 €	4,90 €	5,03 €	
Q61801	12	21	5	20 000	1 920	1 040	✓	5,16 €	4,90 €	4,90 €	
Q6001	12	28	8	18 000	5 100	2 370	✓	3,56 €	3,70 €	3,81 €	
Q6201	12	32	10	17 000	6 800	3 050	✓	4,22 €	4,09 €	4,22 €	
Q6301	12	37	12	16 000	9 700	4 200	✓	6,66 €	6,10 €	5,16 €	
Q61802	15	24	5	17 000	2 070	1 260	✓	5,16 €	5,56 €	5,44 €	
Q6002	15	32	9	15 000	5 600	2 830	✓	4,22 €	4,09 €	4,22 €	
Q6202	15	35	11	14 000	7 650	3 750	✓	4,63 €	4,49 €	4,36 €	
Q6302	15	42	13	13 000	11 400	5 450	-	6,89 €	5,84 €	6,10 €	
Q61803	17	26	5	15 000	2 630	1 570	✓	5,98 €	6,36 €	6,36 €	
Q6003	17	35	10	13 000	6 000	3 250	✓	4,76 €	4,49 €	4,49 €	
Q6203	17	40	12	12 000	9 550	4 800	✓	6,49 €	5,16 €	5,30 €	
Q6303	17	47	14	11 000	13 600	6 650	-	10,91 €	7,19 €	7,30 €	

*Depending on availability - Dimensions in mm

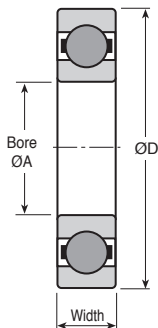

DISCOUNTS

Qty	1+	6+	20+	40+	60+	100+
Disc.	List	-10%	-15%	-20%	-30%	On request

Part number	Bore ØA	ØD	Width	Max. speed (rpm)	Dynamic load (N)	Static load (N)	Stock*	Price each 1 to 5		
								2RS	Open	ZZ
Q61804	20	32	7	13 000	4 000	2 470	✓	7,19 €	7,98 €	6,76 €
Q6004	20	42	12	11 000	9 400	5 000	✓	6,36 €	5,56 €	5,56 €
Q6204	20	47	14	11 000	12 800	6 600	✓	7,98 €	6,10 €	6,23 €
Q6304	20	52	15	10 000	15 900	7 900	✓	11,19 €	7,98 €	8,23 €
Q61805	25	37	7	10 000	4 300	2 950	✓	10,78 €	9,70 €	9,70 €
Q6005	25	47	12	9 500	10 100	5 850	✓	6,49 €	6,10 €	6,23 €
Q6205	25	52	15	9 000	14 000	7 850	✓	8,89 €	7,30 €	7,44 €
Q61806	30	42	7	9 000	4 500	3 450	✓	11,45 €	11,83 €	12,92 €
Q6006	30	55	13	8 000	13 200	8 300	✓	10,91 €	7,19 €	7,30 €
Q6206	30	62	16	7 500	19 500	11 300	✓	14,12 €	9,70 €	9,85 €
Q61807	35	47	7	7 500	4 750	3 900	-	13,84 €	16,40 €	14,93 €
Q6007	35	62	14	6 700	16 000	10 300	-	12,12 €	8,50 €	8,65 €
Q6207	35	72	17	6 300	25 700	15 300	✓	18,39 €	12,50 €	12,78 €
Q61808	40	52	7	6 700	4 900	4 350	-	19,05 €	20,40 €	20,14 €
Q6008	40	68	15	6 000	16 800	11 500	✓	18,14 €	9,85 €	9,98 €
Q6208	40	80	18	5 600	29 100	17 800	✓	23,88 €	15,32 €	15,73 €
Q61809	45	58	7	6 000	5 350	5 250	-	26,30 €	34,30 €	26,02 €
Q6009	45	75	16	5 300	20 900	15 200	-	17,85 €	11,99 €	12,38 €
Q6209	45	85	19	5 300	31 500	20 400	-	27,09 €	18,14 €	18,39 €
Q61810	50	65	7	5 300	6 400	6 200	-	31,10 €	90,85 €	34,57 €
Q6010	50	80	16	4 800	21 800	16 600	-	23,88 €	14,66 €	14,01 €
Q6210	50	90	20	4 800	35 000	23 200	-	On request	20,28 €	20,79 €

*Depending on availability - Dimensions in mm