

Freewheel with internal bearing

Self centering

QUK
QUKC

- Transmits torque in one direction, free movement in the other
- Keyway conforms to DIN6885
- Max torque = 2 x TN
- Material: steel

Assembly

- **QUK:**
Shaft tolerance n6
Housing tolerance N6
- **QUKC:**
Shaft tolerance k6
Housing tolerance N6

Info


- Self centering freewheel, pre-greased and fitted with anti-dust protection




QUK



QUKE

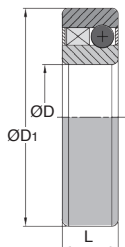

QUK

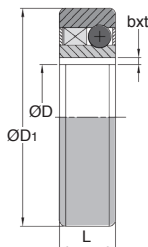

QUKE

DISCOUNTS

Qty	1+	6+	30+
Disc	List	-6%	On request

Part number	ØD	ØD1 (h5)	b L (Js9)	t	Bearing type	Load capacity		Torque	Residual	Weight (kg)	Price each 1 to 5	
						Dynamic (N)	Static (N)	Tn (Nm)	torque (Nm)			
Without keyway												
QUK15 ZZ	15 ^{-0,01}	35	11	-	-	6202ZZ	7400	3400	16,9	0,009	0,06	38,54 €
QUK17 ZZ	17 ^{-0,01}	40	12	-	-	6203ZZ	7900	3800	30,6	0,011	0,07	34,78 €
QUK20 ZZ	20 ^{-0,01}	47	14	-	-	6204ZZ	9400	4450	50,0	0,013	0,11	39,82 €
QUK25 ZZ	25 ^{-0,01}	52	15	-	-	6205ZZ	10700	5450	85,0	0,020	0,14	41,84 €
QUK30 ZZ	30 ^{-0,01}	62	16	-	-	6206ZZ	11700	6450	138,0	0,044	0,21	52,71 €
With keyway												
QUKC15 ZZ	15H7	35	11	5	1,2	6202ZZ	7400	3400	16,9	0,009	0,06	41,69 €
QUKC17 ZZ	17H7	40	12	5	1,2	6203ZZ	7900	3800	30,6	0,011	0,07	38,06 €
QUKC20 ZZ	20H7	47	14	6	1,6	6204ZZ	9400	4450	50,0	0,013	0,11	42,65 €
QUKC25 ZZ	25H7	52	15	8	2,0	6205ZZ	10700	5450	85,0	0,020	0,14	44,34 €
QUKC30 ZZ	30H7	62	16	8	2,0	6206ZZ	11700	6450	138,0	0,044	0,21	56,31 €

Dimensions in mm