

Stainless steel worm and wheel gearbox

Torque up to 80 Nm

RFV50

- Gearbox especially suitable for use in the food industry
- Ratios from 7.5:1 to 100:1
- B14 flange
- All surfaces smooth and polished to avoid dirt retention
- Lubricated using food quality grease
- Working temperature: -20° to +40 °C
- Material:

316 stainless steel housing

Accessories

- Use with a DER 4 pole motor to create a motorised gearbox
- Torque arm, mounting feet and protective covers


Info

- All information is engraved directly on to gearbox rather than being on a tag plate to avoid accumulating dirt etc



stainless steel

Suitable for the food industry

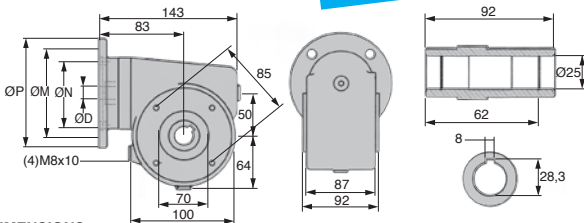

FLANGE DIMENSIONS

	ØD	ØP	ØM	ØN
63B14 flange	11	90	75	60
71B14 flange	14	105	85	70
80B14 flange	19	120	100	80

DISCOUNTS

Qty	1+	2+	4+
Disc.	List	-5%	On request

	Part number	Reduction ratio	Self locking output	Price each	
63B14 flange	71B14 flange	80B14 flange			
-	RFV50-7,5-71B14/SS	RFV50-7,5-80B14/SS	7,5	No	615,49 €
-	RFV50-10-71B14/SS	RFV50-10-80B14/SS	10	No	615,49 €
-	RFV50-15-71B14/SS	RFV50-15-80B14/SS	15	No	615,49 €
-	RFV50-20-71B14/SS	RFV50-20-80B14/SS	20	Not defined	615,49 €
-	RFV50-25-71B14/SS	RFV50-25-80B14/SS	25	Not defined	615,49 €
-	RFV50-30-71B14/SS	RFV50-30-80B14/SS	30	Yes	615,49 €
-	RFV50-40-71B14/SS	-	40	Yes	615,49 €
RFV50-50-63B14/SS	RFV50-50-71B14/SS	-	50	Yes	615,49 €
RFV50-60-63B14/SS	RFV50-60-71B14/SS	-	60	Yes	615,49 €
RFV50-80-63B14/SS	RFV50-80-71B14/SS	-	80	Yes	615,49 €
RFV50-100-63B14/SS	-	-	100	Yes	615,49 €

Dimensions in mm