



- Supplied by the roll
- Can be fixed to sheet metal or thin panels

### Characteristics of EPDM


- Hardness 30 to 90 Shore A
- Working temperature: -35°C to +120°C
- Very good ozone, acid, hot water, and ageing resistance
- Almost impermeable to gas
- Good alkaline resistance
- No resistant to oils or some other hydrocarbons
- Flammable

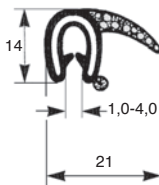

RJA10-03

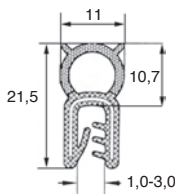

RJA10-10

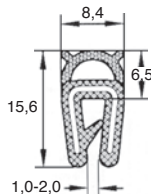

RJA00-25

### DISCOUNTS for 5m DISCOUNTS for 25m & 50m

Qty	1+	5+	50+
Disc.	List	-10%	Request

Qty	1+	3+	6+
Disc.	List	-10%	On request

Part number	Material	Supplied in rolls of	Stock*	Price each
RJA10-03/5	Black EPDM	5 metres	✓	36,81 €
RJA10-03/50	Black EPDM	50 metres	-	147,39 €
RJA10-10/5	Black EPDM	5 metres	✓	38,26 €
RJA10-10/25	Black EPDM	25 metres	✓	152,89 €
RJA00-25/5	Black EPDM	5 metres	✓	36,81 €
RJA00-25/50	Black EPDM	50 metres	✓	294,87 €

\*Depending on availability - Dimensions in mm