



- Open housing for open bearing
- Bearing not supplied
- Material : Aluminium

Options

- Compatible with KB-OP and TK-OP ranges

Advantages

- Use with long supported shafts to avoid flexing.

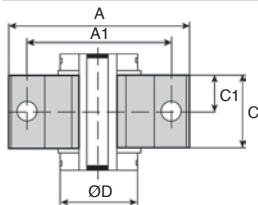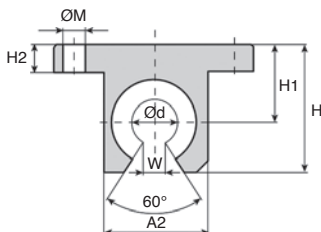

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	For shaft Ød	ØD	H	C	A	A1 +/-0.15
S2012	12	22	28,0	20	52	42
S2016	16	26	33,5	22	56	46
S2020	20	32	42,0	28	70	58
S2025	25	40	51,0	40	80	68
S2030	30	47	60,0	48	88	76
S2040	40	62	77,0	56	108	94
S2050	50	75	93,0	72	135	116

Part number	C1	H1 +/-0.015	H2	W	A2	ØM	Price each 1 to 4
S2012	10	18	6	7,0	30	5,3	On request
S2016	11	22	7	9,4	34	5,3	43,11 €
S2020	14	25	8	10,0	40	6,4	45,05 €
S2025	20	30	10	12,5	50	6,4	58,91 €
S2030	24	35	10	12,5	58	6,4	79,92 €
S2040	28	45	12	16,8	74	8,4	100,86 €
S2050	36	50	12	21,0	96	10,5	141,95 €

*Depending on availability - Dimensions in mm