



Chain sprocket DIN 05B-1


Steel

Pitch
8mm

- Pitch 8mm (DIN 05B-1) S
- Roller diameter 5mm
- Material:
Steel 20NCD2

Accessories

- SBR-8 or SBS-8 chains

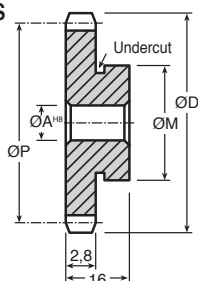

stainless
steel

DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-5%	-10%	On request

Part number	Z Teeth	ØP	ØD	ØM	ØA	Undercut Ø x width	Price each 1 to 5	
							S	AS
S 8-8	8	20,90	24,11	14	6	11,37 x 3	12,97 €	10,93 €
S 8-9	9	23,39	26,78	14	6	-	13,22 €	11,04 €
S 8-10	10	25,89	29,42	17	8	-	13,84 €	11,57 €
S 8-11	11	28,40	32,04	18	8	-	13,82 €	11,57 €
S 8-12	12	30,90	34,65	20	8	-	13,82 €	11,57 €
S 8-13	13	33,42	37,25	20	8	-	13,98 €	11,70 €
S 8-14	14	35,95	39,84	20	8	-	14,06 €	11,80 €
S 8-15	15	38,48	42,48	28	8	-	14,31 €	12,04 €
S 8-16	16	41,00	45,00	30	8	-	14,65 €	12,28 €
S 8-17	17	43,53	47,53	30	8	-	15,06 €	12,68 €
S 8-18	18	46,07	50,16	30	8	-	15,58 €	13,02 €
S 8-19	19	48,61	52,74	30	8	-	16,01 €	13,42 €
S 8-20	20	51,14	55,31	30	8	-	16,48 €	13,84 €
S 8-21	21	53,67	57,88	30	8	-	17,45 €	14,68 €
S 8-23	23	58,75	63,00	30	8	-	17,85 €	14,94 €
S 8-25	25	63,82	68,12	35	10	-	17,90 €	16,01 €
S 8-27	27	68,91	73,24	35	10	-	24,15 €	20,29 €
S 8-30	30	76,53	80,91	40	10	-	25,98 €	21,80 €
S 8-33	33	84,16	88,58	40	10	-	27,88 €	23,34 €
S 8-35	35	89,24	93,68	40	10	-	28,45 €	23,93 €
S 8-36	36	91,78	96,24	40	12	-	29,53 €	24,78 €
S 8-38	38	96,87	101,34	40	12	-	31,16 €	26,09 €
S 8-40	40	101,96	106,44	40	12	-	33,15 €	27,83 €
S 8-42	42	107,05	111,55	40	12	-	33,90 €	28,45 €
S 8-44	44	112,14	116,65	40	12	-	37,48 €	31,45 €
S 8-48	48	122,31	126,85	40	12	-	43,74 €	36,71 €
S 8-50	50	127,40	131,96	40	12	-	47,16 €	39,58 €

Dimensions in mm