

- Closed housing
- SA: Housing only
SAKH: Housing and light KH bearing with seal
- Material: anodised aluminium

Accessories



- Hardened ground shafts
Z-A, Z-B
- End support for shafts FGWA, SFWR



SA: housing only



SAKH: housing + KH bearing

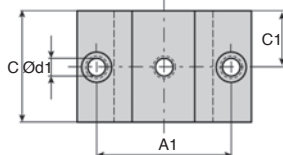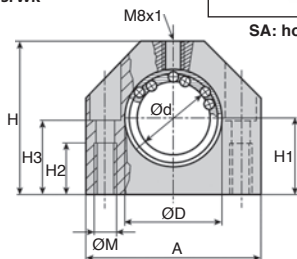

DISCOUNTS

Qty	1+	5+	10+	25+
Disc.	List	-6%	-12%	On request

Part number	Housing only	Housing and bearing	For shaft Ød	ØD	A	C	H	A1 +/-0,15	C1
SA12	SAKH-12-LL		12	19	40	28	33	29	14
SA16	SAKH-16-LL		16	24	45	30	38	34	15
SA20	SAKH-20-LL		20	28	53	30	45	40	15
SA25	SAKH-25-LL		25	35	62	40	54	48	20
SA30	SAKH-30-LL		30	40	67	50	60	53	25
SA40	SAKH-40-LL		40	52	87	60	76	69	30
SA50	SAKH-50-LL		50	62	103	70	92	82	35

Part number	Housing only	Housing and bearing	H1 +0,010 -0,02	H2	H3	ØM	Ød1	Stock* Housing + bearing	Price each 1 to 4 Housing only + bearing
SA12	SAKH-12-LL		17	11	16	M5	4,3	✓	35,07 € 49,79 €
SA16	SAKH-16-LL		19	11	18	M5	4,3	✓	36,65 € 55,56 €
SA20	SAKH-20-LL		23	13	22	M6	5,3	✓	40,85 € 61,84 €
SA25	SAKH-25-LL		27	18	26	M8	6,6	✓	51,37 € 74,43 €
SA30	SAKH-30-LL		30	18	29	M8	6,6	✓	67,07 € 98,58 €
SA40	SAKH-40-LL		39	22	38	M10	8,4	-	99,62 € 145,79 €
SA50	SAKH-50-LL		47	26	46	M12	10,5	-	131,12 € 188,83 €

*Depending on availability - Dimensions in mm