

Single chain supplied by the metre **Sta** **DIN** **Stock**



Pitch 9.52 to 19.05 mm

Stainless steel

- DIN 8187 (European Standard)
- ISO 606
- Compatible with standard HPC sprockets
- Supplied in multiples of 5 metres

Accessories

- BTE/SS arm and PTR/SS idler
- Roll-Ring® RLR idler

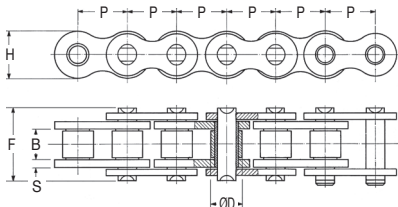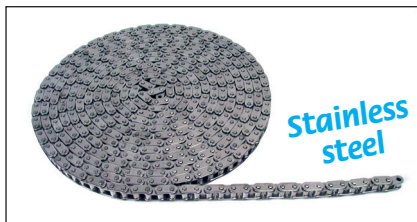

DISCOUNTS

No metres	1+	10+	25+
Discounts	List	-10%	On request

Part number	DIN	Pitch P (mm)	B (mm)	Roller ØD (mm)	F (mm)	H (mm)	S (mm)	Breaking strength (kN)	Sold in multiples of	Price per metre
SBS-375/M 06B-1		9,52	5,72	6,35	14,0	8,3	1,3	9	5 metres	✓ 32,72 €
SBS-500/M 08B-1		12,70	7,75	8,51	18,7	11,8	1,6	18	5 metres	✓ 37,77 €
SBS-625/M 10B-1		15,88	9,65	10,16	21,1	14,7	1,70	22,4	5 metres	✓ 52,66 €
SBS-750/M 12B-1		19,05	11,68	12,07	24,5	16,1	1,85	29	5 metres	✓ 60,38 €

*Depending on availability - Dimensions in mm