

- 2 materials to choose from

- Materials:

SEH body: zinc plated steel

SEH/SS body: stainless steel 18.9 (303)

Handle: Oil-resistant plastic


- Supplied with anchoring base

Advantages

- Distance of hook from toggle clamp easily adjustable

Uses

- Designed to secure covers and shutters

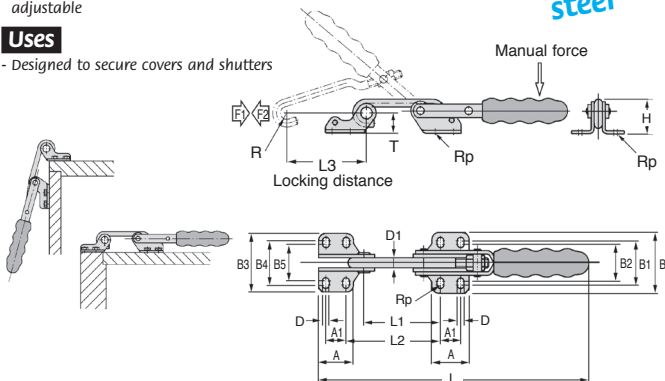

DISCOUNTS

Qty	1+	6+	15+	20+
Disc.	List	-5%	-10%	On request

Size	Traction force F1 (N)	Pressure F2 (N)	Manual force (N)	Handle opening angle	L	L1	L2	Locking distance L3	A	A1
SCH-01	1500	2000	100	155°	161	45	58	70	26	13
SCH-02	3000	4000	160	155°	248	68	84	90	35	19
SCH-04	4000	7000	200	155°	310	84	104	115	51	32

Part number													Stock*		Price each 1 to 5	
Steel	Stainless steel	B	B1	B2	B3	B4	B5	D	D1	H	R	T	Steel	StS	Steel	StS
SCH-0130	SCH-0130SS	39	27,0	22,2	43	31	26	5,2	6	26	6	13,5	✓	✓	49,79 €	58,05 €
SCH-0270	SCH-0270SS	52	36,0	29,0	57	41	34	6,5	8	35	7	20,0	✓	✓	73,57 €	87,73 €
SCH-0430	SCH-0430SS	72	52,5	43,5	78	59	50	8,5	12	49	10	27,0	-	-	93,21 €	183,19 €

*Subject to availability - Dimensions in mm