

Parallel axis helical gear



Module



Steel

0.4

- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2

Info.

Important: a right handed gear only meshes with a left handed gear.

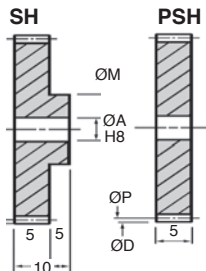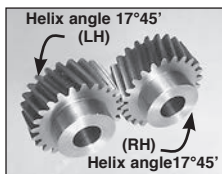

Torque and power indication			
For 50 teeth at 1000 rpm			
	20NCD2 Z10CNF18.09	20NCD2 hardened	brass
Nm	0.28	1.12	0.14
kW	0.03	0.12	0.01

DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	ØP PCD	ØD Outside	ØM Boss	ØA Bore	Price each 1 to 5	SH	PSH
SH0.4-10	10	4,62	5,42	5,42	2	17,20 €		
SH0.4-15	15	6,30	7,10	7,10	2	17,32 €		
SH0.4-20	20	8,40	9,20	8,00	3	17,32 €		
SH0.4-25	25	10,50	11,30	8,00	3	17,29 €		
SH0.4-30	30	12,60	13,40	8,00	3	17,50 €		
SH0.4-35	35	14,70	15,50	8,00	3	17,95 €		
SH0.4-40	40	16,80	17,60	12,00	4	18,38 €		
SH0.4-45	45	18,90	19,70	12,00	4	19,04 €		
SH0.4-50	50	21,00	21,80	12,00	4	19,62 €		
SH0.4-55	55	23,10	23,90	12,00	4	20,18 €		
SH0.4-60	60	25,20	26,00	12,00	4	21,06 €		
SH0.4-65	65	27,30	28,10	12,00	4	22,09 €		
SH0.4-70	70	29,40	30,20	12,00	4	22,39 €		
SH0.4-75	75	31,50	32,30	12,00	4	22,67 €		
SH0.4-80	80	33,60	34,40	12,00	5	23,07 €		
SH0.4-86	86	36,12	36,92	12,00	5	23,92 €		
SH0.4-90	90	37,80	38,60	12,00	5	24,80 €		
SH0.4-100	100	42,00	42,80	12,00	5	25,70 €		
SH0.4-120	120	50,40	51,20	12,00	5	26,05 €		
SH0.4-140	140	58,80	59,60	12,00	5	28,37 €		
SH0.4-150	150	63,00	63,80	12,00	5	29,25 €		
SH0.4-180	180	75,60	76,40	15,00	6	41,24 €		
SH0.4-200	200	84,00	84,80	15,00	8	46,32 €		
SH0.4-220	220	92,40	93,20	15,00	8	On request		
SH0.4-250	250	105,00	105,80	20,00	10	60,59 €		
↓ Gears available up to this size ↓								
SH0.4-330	330	Dimensions: contact us				On request		

Dimensions in mm

On request