



Steel or **machined** plastic

Module 2.0

- Gears are in permanent contact
- Reduced noise
- Pressure angle 20°
- Material: Steel 20NCD2 or delrin plastic

Info.

Important: a right handed gear only meshes with a left handed gear.

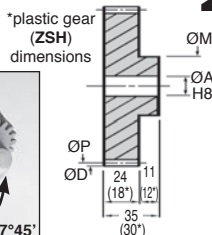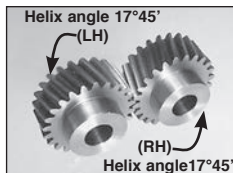

Torque and power indication

For 50 teeth at 1000 rpm

	20NCD2 Z10CNF18.09	20NCD2 hardened	brass	delrin
Nm	33.89	134.0	16.94	8.0
kW	3.56	14.0	1.78	-

Steel DISCOUNTS

Qty	1+	6+	20+	40+
Disc.	List	-12%	-25%	On request

Plastic DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number	Z	ØP	ØD	ØM	Boss	ØA	Bore	Price each 1 to 5
Steel	Plastic	Teeth	PCD	Outside	SH	ZSH	SH	ZSH
SH2-10	ZSH2-10	10	21,00	25,00	25	24	12	10
SH2-15	ZSH2-15	15	31,50	35,50	25	25	15	12
SH2-18	ZSH2-18	18	37,80	41,80	30	30	15	12
SH2-20	ZSH2-20	20	42,00	46,00	30	30	15	12
SH2-22	ZSH2-22	22	46,20	50,20	35	30	15	12
SH2-24	ZSH2-24	24	50,40	54,40	35	30	15	12
SH2-25	ZSH2-25	25	52,50	56,50	35	30	15	12
SH2-30	ZSH2-30	30	63,00	67,00	40	30	20	12
SH2-32	ZSH2-32	32	67,20	71,20	40	30	20	12
SH2-35	ZSH2-35	35	73,50	77,50	50	30	20	12
SH2-40	ZSH2-40	40	84,00	88,00	50	35	20	12
SH2-45	ZSH2-45	45	94,50	98,50	50	35	20	15
SH2-48	ZSH2-48	48	100,80	104,80	50	35	20	15
SH2-50	ZSH2-50	50	105,00	109,00	50	35	20	15
SH2-55	ZSH2-55	55	115,50	119,50	50	35	20	15
SH2-56	ZSH2-56	56	117,60	121,60	50	35	20	15
SH2-60	ZSH2-60	60	126,00	130,00	50	35	20	15
SH2-65	ZSH2-65	65	136,50	140,50	50	40	20	15
SH2-70	ZSH2-70	70	147,00	151,00	50	40	20	15
SH2-75	ZSH2-75	75	157,50	161,50	50	50	20	15
SH2-80	-	80	168,00	172,00	50	-	20	-
SH2-90	-	90	189,00	193,00	50	-	20	-
SH2-100	-	100	210,00	214,00	50	-	20	-
SH2-110	-	110	231,00	235,00	50	-	20	-
SH2-120	-	120	252,00	256,00	50	-	20	-

SH2-280	ZSH2-280	280	dimensions: contact us	On request	On request
---------	----------	-----	------------------------	------------	------------

Dimensions in mm