

Stainless steel 304L


Ratio

2:1

3:1

4:1

- Module 0.8 to 2.5
- Teeth Gleason
- Material:
stainless steel 304L
- Pressure angle 20°

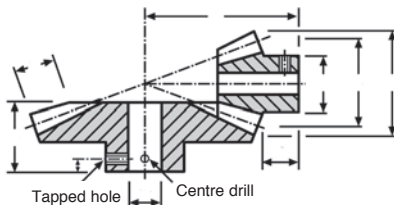

stainless steel

TORQUE AND POWER INDICATION	For 20 teeth at 1000 rpm					
	2.5 MOD	2.0 MOD	1.5 MOD	1.25 MOD	1.0 MOD	0.8 MOD
Torque (Nm)	4.30	2.20	0.94	0.71	0.57	0.14
Power (kW)	0.455	0.231	0.097	0.08	0.03	0.015

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-12%	On request

Part number	Teeth		Z	Module	ØP	E	ØD	ØA	ØM	F	G	H	Screw		Price each 1 to 5
													R	T	
SSDB0.8-15	15	0,8	15	1	12,00	20,00	13,93	6	10	11,90	7,50	4,02	M3	3,50	46,73 €
SSDB0.8-30	30		30		24,00	14,00	24,64	8	20	10,08	5,50	4,02	M3	3,50	55,09 €
SSDB1-15	15	2:1	15	1	15,00	24,00	17,42	8	14	13,87	8,76	5,03	M4	4,00	52,99 €
SSDB1-30	30		30		30,00	18,00	30,58	10	25	13,11	7,00	5,03	M4	4,00	65,15 €
SSDB1.5-15	15	1,5	15	1,5	22,50	35,00	26,12	10	21	19,84	12,13	7,55	M4	5,00	57,68 €
SSDB1.5-30	30		30		45,00	27,00	45,87	10	30	19,66	11,00	7,55	M4	5,00	74,05 €
SSDB2-15	15	2	15	2	30,00	45,00	34,83	12	28	24,76	14,86	10,06	M5	7,50	63,95 €
SSDB2-30	30		30		60,00	35,00	61,16	12	40	25,21	14,00	10,06	M5	8,00	88,65 €
SSDB2.5-15	15	2,5	15	2,5	37,50	54,00	43,54	15	32	29,51	16,51	13,53	M5	8,00	87,37 €
SSDB2.5-30	30		30		75,00	41,50	76,45	15	30	29,31	13,31	13,53	M5	7,00	121,37 €
SSTB0.8-15	15	0,8	15	0,8	12,00	28,00	14,14	6	10	15,63	9,67	5,69	M3	5,00	On request
SSTB0.8-45	45		45		36,00	20,00	36,30	8	28	16,07	8,00	5,69	M3	4,00	
SSTB1-15	15	3:1	15	1	15,00	32,00	17,67	8	13	16,54	9,18	7,12	M4	4,50	
SSTB1-45	45		45		45,00	24,00	45,37	10	40	19,09	10,00	7,12	M4	5,00	
SSTB1.5-15	15	1,5	15	1,5	22,50	45,00	26,51	10	18	21,80	10,51	10,67	M4	5,00	
SSTB1.5-45	45		45		67,50	32,00	68,06	15	50	24,63	12,00	10,67	M4	6,00	
SSFB0.8-15	15	0,8	15	0,8	12,00	35,00	14,23	6	10	18,07	10,58	7,10	M3	5,00	
SSFB0.8-60	60		60		48,00	20,00	48,22	8	30	15,98	8,00	7,10	M3	4,00	
SSFB1-15	15	4:1	15	1	15,00	45,00	17,79	8	13	24,22	14,73	9,28	M4	7,00	
SSFB1-60	60		60		60,00	30,00	60,27	10	40	25,08	12,00	9,28	M4	6,00	
SSFB1.5-15	15	1,5	15	1,5	22,50	60,00	26,69	10	18	28,82	12,08	13,91	M4	6,00	
SSFB1.5-60	60		60		60,00	35,00	90,41	15	50	27,61	12,00	13,91	M4	6,00	

Dimensions in mm