

T-type belt



Pitch T10

Polyurethane with steel core

- Pitch 10mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%

Options

- Belt by the metre **T10M**
- Alternative lengths/widths

Accessories

- BTE arm and GTC roller belt tensioner

Info.

- When ordering, add the width to the part number.

Eg: T10/120/4



Compatible with T10 pulley


 
DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Price each 1 to 5 for width			
			16mm	25mm	32mm	50mm
T 10/260	260	26	25,34 €	35,16 €	On request	On request
T 10/370	370	37	27,41 €	38,27 €		
T 10/410	410	41	28,40 €	39,48 €		
T 10/500	500	50	30,69 €	41,98 €		
T 10/530	530	53	31,40 €	43,04 €		
T 10/560	560	56	32,65 €	44,51 €		
T 10/600	600	60	33,58 €	45,55 €		
T 10/610	610	61	33,70 €	46,05 €		
T 10/630	630	63	34,70 €	47,03 €		
T 10/660	660	66	35,71 €	48,54 €		
T 10/680	680	68	31,91 €	53,70 €		
T 10/690	690	69	36,72 €	50,10 €		
T 10/700	700	70	38,17 €	45,42 €		
T 10/720	720	72	37,96 €	51,84 €		
T 10/730	730	73	36,37 €	56,73 €		
T 10/750	750	75	40,08 €	58,04 €		

Dimensions in mm

Pitch T10

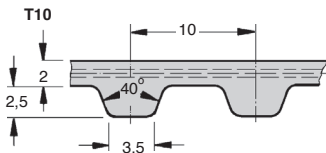

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Price each 1 to 5 for width			
			16mm	25mm	32mm	50mm
T 10/780	780	78	40,25 €	55,10 €	On request	On request
T 10/810	810	81	41,49 €	56,84 €		
T 10/840	840	84	42,78 €	58,67 €		
T 10/880	880	88	44,25 €	61,17 €		
T 10/890	890	89	44,75 €	62,19 €		
T 10/920	920	92	46,05 €	64,18 €		
T 10/960	960	96	47,54 €	67,18 €		
T 10/970	970	97	48,06 €	68,01 €		
T 10/980	980	98	48,54 €	68,70 €		
T 10/1010	1010	101	50,10 €	70,75 €		
T 10/1080	1080	108	52,85 €	75,27 €		
T 10/1110	1110	111	54,53 €	83,86 €		
T 10/1140	1140	114	55,63 €	79,35 €		
T 10/1150	1150	115	55,86 €	79,79 €		
T 10/1210	1210	121	58,67 €	84,09 €		
T 10/1240	1240	124	60,21 €	85,81 €		
T 10/1250	1250	125	60,38 €	86,63 €		
T 10/1300	1300	130	62,89 €	89,94 €		
T 10/1320	1320	132	63,69 €	91,15 €		
T 10/1350	1350	135	64,98 €	93,17 €		
T 10/1390	1390	139	66,96 €	95,98 €		
T 10/1400	1400	140	67,47 €	96,44 €		
T 10/1420	1420	142	68,24 €	97,67 €		
T 10/1460	1460	146	70,00 €	100,26 €		
T 10/1500	1500	150	sur demande	111,37 €		
T 10/1560	1560	156	73,03 €	106,27 €		
T 10/1610	1610	161	76,81 €	110,05 €		
T 10/1750	1750	175	83,60 €	120,65 €		
T 10/1780	1780	178	85,10 €	122,88 €		
T 10/1880	1880	188	90,14 €	130,47 €		
T 10/1960	1960	196	95,69 €	138,02 €		
T 10/2250	2250	225	118,11 €	173,42 €		

Dimensions in mm