

T-type timing pulley



Pitch

Aluminium

T2.5

Belt width 4mm


- Pitch 2.5mm

- Materials:

Pulley: Aluminium 6082

Flanges: Aluminum for pulleys with up to 84 teeth, steel for 85 teeth or more

- All pulleys have flanges

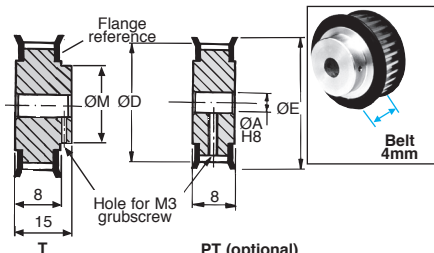

Options

- Choose from 10 to 230 teeth



DISCOUNTS

Qty	1+	6+	20+	50+
Disc.	List	-12%	-25%	On request

Part number	Z Teeth	Ø PCD	ØD	ØM	ØA	Flange ref.	ØE	Stock*	Price each 1 to 5 T PT
10T2.5-8	10	7,96	7,40	13	3	10 X,Y	13,00	✓	On request
12T2.5-8	12	9,55	9,00	13	3	10 X,Y	13,00	✓	
14T2.5-8	14	11,14	10,60	18	3	16 X,Y	18,00	✓	
15T2.5-8	15	11,94	11,40	18	3	16 X,Y	18,00	✓	
16T2.5-8	16	12,73	12,20	18	4	16 X,Y	18,00	✓	
18T2.5-8	18	14,32	13,80	18	4	31 X,Y	18,00	✓	
19T2.5-8	19	15,12	14,60	20	4	32 X,Y	20,00	✓	
20T2.5-8	20	15,92	15,40	20	4	32 X,Y	20,00	✓	
21T2.5-8	21	16,71	16,20	20	4	32 X,Y	20,00	-	
22T2.5-8	22	17,51	17,00	20	4	32 X,Y	20,00	✓	
24T2.5-8	24	19,10	18,55	13	4	12 XL	25,15	-	
25T2.5-8	25	19,89	19,35	13	4	12 XL	25,15	✓	
26T2.5-8	26	20,69	20,15	13	5	12 XL	25,15	✓	
30T2.5-8	30	23,87	23,35	20	5	16 XL	31,74	-	
31T2.5-8	31	24,67	24,15	20	5	18 XL	34,80	-	
32T2.5-8	32	25,46	24,95	20	5	18 XL	34,80	✓	
40T2.5-8	40	31,83	31,30	24	6	21XL	39,68	✓	
44T2.5-8	44	35,01	34,50	24	6	21XL	39,68	-	
48T2.5-8	48	38,20	37,70	24	6	24XL	44,70	✓	
52T2.5-8	52	41,38	40,85	24	6	24XL	44,70	-	
57T2.5-8	57	45,36	44,85	24	6	28XL	51,05	-	
60T2.5-8	60	47,75	47,25	24	6	30XL	54,36	✓	
80T2.5-8	80	63,66	63,16	24	6	17H	74,61	✓	On request
84T2.5-8	84	66,85	66,35	24	6	18H	79,38	-	
Pulleys available up to this size									
230T2.5-8	230	Dimensions : contact us							

*Depending on availability - Dimensions in mm