

- Pitch 2.5mm
- Working temp. -30°C to +80°C
- Max. speed 40m/s
- Efficiency: up to 98%

Options


 
- Belt by the metre **T2.5M**
- Alternative lengths/widths

Accessories

- **BTE** arm and **GTC** roller belt tensioner

Info.

- When ordering, add the width to the part number
Eg: T2.5/120/4

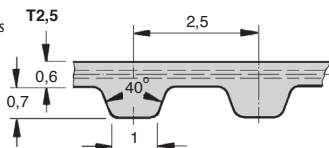

**Compatible with
T2.5 pulley**

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

Part number	Length	No. of teeth	Stock*	Stock*	Price each 1 to 5 for width		
			4mm	6mm	4mm	6mm	10mm
T 2.5/120	120,00	48	✓	✓	9,07 €	10,07 €	On request
T 2.5/145	145,00	58	✓	✓	9,19 €	10,17 €	
T 2.5/160	160,00	64	✓	✓	9,22 €	10,22 €	
T 2.5/177	177,50	71	✓	✓	9,42 €	10,46 €	
T 2.5/180	180,00	72	✓	✓	9,42 €	10,46 €	
T 2.5/182	182,50	73	✓	✓	9,42 €	10,46 €	
T 2.5/200	200,00	80	✓	✓	9,42 €	10,46 €	
T 2.5/230	230,00	92	✓	✓	10,08 €	11,24 €	
T 2.5/245	245,00	98	✓	✓	10,00 €	11,12 €	
T 2.5/265	265,00	106	✓	✓	10,09 €	11,25 €	
T 2.5/285	285,00	114	✓	✓	10,15 €	11,29 €	
T 2.5/290	290,00	116	✓	✓	10,57 €	11,77 €	
T 2.5/317	317,50	127	✓	✓	10,53 €	11,71 €	
T 2.5/330	330,00	132	✓	✓	10,66 €	11,83 €	
T 2.5/380	380,00	152	✓	✓	11,25 €	12,50 €	
T 2.5/420	420,00	168	-	✓	14,35 €	12,47 €	
T 2.5/480	480,00	192	✓	✓	11,66 €	12,94 €	
T 2.5/500	500,00	200	✓	✓	11,83 €	13,13 €	
T 2.5/600	600,00	240	✓	✓	16,19 €	17,99 €	
T 2.5/620	620,00	248	-	✓	16,81 €	18,70 €	
T 2.5/650	650,00	260	-	✓	16,46 €	18,25 €	
T 2.5/780	780,00	312	✓	✓	18,97 €	21,11 €	
T 2.5/950	950,00	380	✓	-	20,96 €	23,31 €	

*Depending on availability - Dimensions in mm