

T-type timing belt **per metre**



Pitch

Steel cored polyurethane

T5

T10

- Pitches: 2.5, 5 and 10mm
- **For linear movement**
- Secured by rigid connection plates
- Working temp. -20°C to +80°C
- Max. speed 40m/s
- Tolerance over length $\pm 0.8\text{mm}/1000\text{mm}$
- Efficiency: up to 98%

Uses

- Alternating back-and-forth movements


Accessories

- Connecting plate T.../P



Info.

- Min. length: 1000mm
- Supplied in multiples of 1 metre
- When ordering, add the length (L) and the width (I) to the part number (T5M/L/I).



E.g.: **T5M/1000/16**

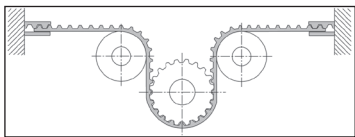

Typical application

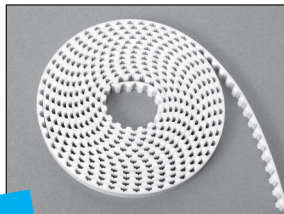 

For linear positioning

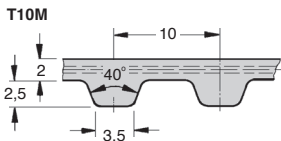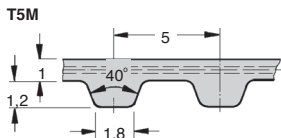

DISCOUNTS

Qty	1+	6+	20+
Disc.	List	-7%	On request

		Price 1 to 5, per metre for width					
Part number	Pitch	6mm	10mm	16mm	25mm	32mm	50mm
T5M	T5	19,28 €	25,10 €	29,75 €	56,10 €	-	-
T10M	T10	-	-	35,26 €	47,98 €	61,95 €	68,25 €

Dimensions in mm