



Stainless steel flanged bearing

2 mounting points

UCFLss


- Self aligning bearing with 2 mounting points
- Interchangeable with cast iron bearings
- Working temperature range: until +140°C
- Material:

Bearing: stainless steel

Housing: stainless steel

For hostile environments

stainless steel

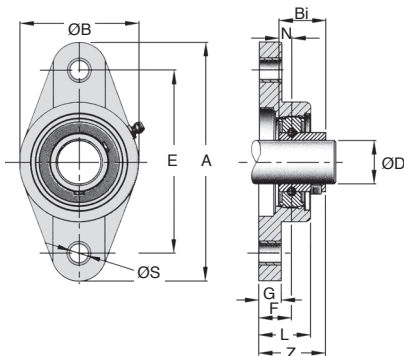

DISCOUNTS

Qty	1+	10+	26+
Disc.	List	-10%	On request

Part number	ØD	A	E	G	L	ØS	Z	F	ØB	Bi	N	Weight (kg)	Price each	
													Stock*	1 to 9
UCFL204/SS	20	113	90	10	25,5	12	33,3	15	60	31,0	12,7	0,48	✓	36,72 €
UCFL205/SS	25	130	99	10	27,0	16	35,8	16	68	34,1	14,3	0,63	✓	44,88 €
UCFL206/SS	30	148	117	10	31,0	16	40,2	18	80	38,1	15,9	0,89	✓	64,30 €
UCFL207/SS	35	161	130	11	34,0	16	44,4	19	90	42,9	17,5	1,21	-	86,33 €
UCFL208/SS	40	175	144	11	36,0	16	51,2	21	100	49,2	19,0	1,60	-	109,87 €

*Depending on availability - Dimensions in mm