

# Retaining catch, single sided

## VRC1

## Indexed 4 x 90°

### Adjustable retaining catch

- To be used for door locking, drawers and as handling aid.

- Material :


 

Body :

Die cast zinc, black similar to RAL 9005

Die cast zinc, silver similar to RAL 9006

Internal pieces : Sintered metal

Screw : A2 stainless steel (ISO 10642)

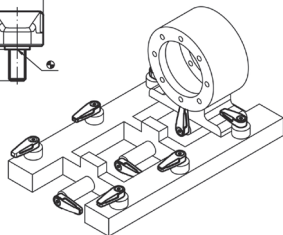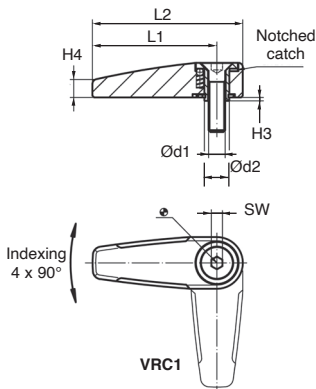

Typical application



### DISCOUNTS

| Qty   | 1+   | 6+   | 20+        |
|-------|------|------|------------|
| Disc. | List | -10% | On request |

| Part number | Colour | Ød1 | Ød2 | L1 | L2 | B    | H1 | H2   | H3  | H4  | SW | Weight (g) | Price each 1 to 5 |
|-------------|--------|-----|-----|----|----|------|----|------|-----|-----|----|------------|-------------------|
| VRC1-M6/A   | Silver | M6  | 9   | 45 | 55 | 19,0 | 12 | 13,3 | 0,8 | 6,5 | 4  | 59         | 20,13 €           |
| VRC1-M8/A   | Silver | M8  | 14  | 65 | 78 | 25,2 | 14 | 15,8 | 0,8 | 9,0 | 5  | 136        | 25,18 €           |
| VRC1-M6/N   | Black  | M6  | 9   | 45 | 55 | 19,0 | 12 | 13,3 | 0,8 | 6,5 | 4  | 59         | 20,13 €           |
| VRC1-M8/N   | Black  | M8  | 14  | 65 | 78 | 25,2 | 14 | 15,8 | 0,8 | 9,0 | 5  | 136        | 25,18 €           |

\*Depending on availability - Dimensions in mm

# Retaining catch, dual sided

Indexed 4 x 90°

VRC2

## Adjustable retaining catch

- To be used for door locking, drawers and as handling aid.

- Material :


Body :

Die cast zinc, black similar to RAL 9005


Die cast zinc, silver similar to RAL 9006

Internal pieces : Sintered metal

Screw : A2 stainless steel (ISO 10642)

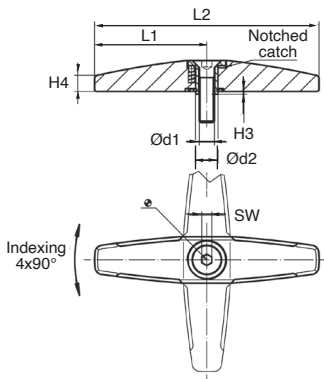

VRC2

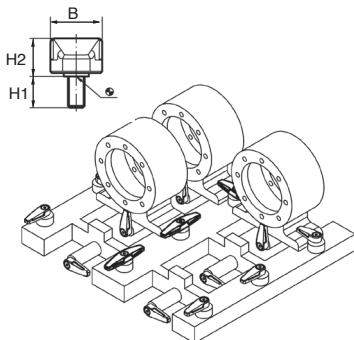

Typical application



## DISCOUNTS

| Qty   | 1+   | 6+   | 20+        |
|-------|------|------|------------|
| Disc. | List | -10% | On request |

| Part number | Colour | Ød1 | Ød2 | L1 | L2  | B    | H1 | H2   | H3  | H4  | SW | Weight (g) | Price each 1 to 5 |
|-------------|--------|-----|-----|----|-----|------|----|------|-----|-----|----|------------|-------------------|
| VRC2-M6/A   | Silver | M6  | 9   | 45 | 90  | 19,0 | 12 | 13,3 | 0,8 | 6,5 | 4  | 93         | 22,53 €           |
| VRC2-M8/A   | Silver | M8  | 14  | 65 | 130 | 25,2 | 14 | 15,8 | 0,8 | 9,0 | 5  | 220        | 29,13 €           |
| VRC2-M6/N   | Black  | M6  | 9   | 45 | 90  | 19,0 | 12 | 13,3 | 0,8 | 6,5 | 4  | 93         | 22,53 €           |
| VRC2-M8/N   | Black  | M8  | 14  | 65 | 130 | 25,2 | 14 | 15,8 | 0,8 | 9,0 | 5  | 220        | 29,13 €           |

\*Depending on availability - Dimensions in mm