


Delrin

Ratio
2:1
3:1
4:1

- Module 0.8 to 2.5
- Machined parts
- Pressure angle 20°
- Teeth Gleason
- Material:
Delrin plastic
- Working temp. -50° Tapped hole ØR
to +80°C

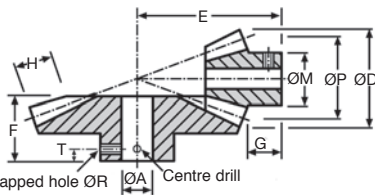

TORQUE AND POWER INDICATION	For 20 teeth at 1000 rpm					
	2.5 MOD	2.0 MOD	1.5 MOD	1.25 MOD	1.0 MOD	0.8 MOD
Torque (Nm)	0.91	0.46	0.20	0.15	0.12	0.03
Power (kW)	0.09	0.05	0.02	0.016	0.013	0.003

DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Teeth													Price each	
Part number	Z	Module	ØP	E	ØD	ØA	ØM	F	G	H	ØR	T	1 to 5	
ZDB0.8-15	15	0.8	12,00	20,00	13,93	6	10	11,90	7,50	4,02	M3	3,50	16,99	€
ZDB0.8-30	30		24,00	14,00	24,64	8	20	10,08	5,50	4,02	M3	3,50	20,09	€
ZDB1-15	15	1	15,00	24,00	17,42	8	14	13,87	8,76	5,03	M4	4,00	19,28	€
ZDB1-30	30		30,00	18,00	30,58	10	25	13,11	7,00	5,03	M4	4,00	23,70	€
ZDB1.5-15	15	1.5	22,50	35,00	26,12	10	21	19,84	12,13	7,55	M4	5,00	26,74	€
ZDB1.5-30	30		45,00	27,00	45,87	10	30	19,66	11,00	7,55	M4	5,00	26,90	€
ZDB2-15	15	2	30,00	45,00	34,83	12	28	24,76	14,86	10,06	M5	7,50	23,24	€
ZDB2-30	30		60,00	35,00	61,16	12	40	25,21	14,00	10,06	M5	8,00	32,33	€
ZDB2.5-15	15	2.5	37,50	54,00	43,54	15	32	29,51	16,51	13,53	M5	8,00	31,81	€
ZDB2.5-30	30		75,00	41,50	76,45	15	50	29,31	13,31	13,53	M5	7,00	40,22	€
ZTB0.8-15	15	0.8	12,00	28,00	14,14	6	10	15,63	9,67	5,69	M3	5,00		
ZTB0.8-45	45		36,00	20,00	36,30	8	28	16,07	8,00	5,69	M3	4,00		
ZTB1-15	15	1	15,00	32,00	17,67	8	13	16,54	9,18	7,12	M4	4,50		
ZTB1-45	45		45,00	24,00	45,37	10	40	19,09	10,00	7,12	M4	5,00		
ZTB1.5-15	15	1.5	22,50	45,00	26,51	10	18	21,80	10,51	10,67	M4	5,00		
ZTB1.5-45	45		67,50	32,00	68,06	15	50	24,63	12,00	10,67	M4	6,00		
ZFB0.8-15	15	0.8	12,00	35,00	14,23	6	10	18,07	10,58	7,10	M3	5,00		
ZFB0.8-60	60		48,00	20,00	48,22	8	30	15,98	8,00	7,10	M3	4,00		
ZFB1-15	15	1	15,00	45,00	17,79	8	13	24,22	14,73	9,28	M4	7,00		
ZFB1-60	60		60,00	30,00	60,27	10	40	25,08	12,00	9,28	M4	6,00		
ZFB1.5-15	15	1.5	22,50	60,00	26,69	10	18	28,82	12,08	13,91	M4	6,00		
ZFB1.5-60	60		60,00	35,00	90,41	15	50	27,61	12,00	13,91	M4	6,00		

Dimensions in mm

On request