

Plastic spur gear




Module 2.5

Machined Delrin



- Machined parts
- Precision class 9
- Pressure angle 20°
- Working temp. -50°C to +80°C

Torque indication	
For 50 teeth at 1000 rpm	
	Delrin
Nm	11

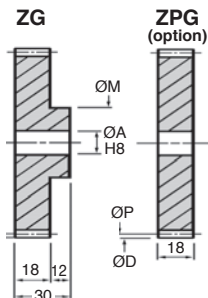

DISCOUNTS

Qty	1+	6+	30+
Disc.	List -22%	On request	On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Weight (kg) ZG	Weight (kg) ZPG	Price each 1 to 5 ZG	Price each 1 to 5 ZPG
ZG2.5-9	9	25,00	30,00	30	10	0,019	0,010	17,34 €	On request
ZG2.5-10	10	27,50	32,50	30	10	0,022	0,012	17,68 €	
ZG2.5-11	11	30,00	35,00	30	10	0,024	0,015	18,07 €	
ZG2.5-12	12	30,00	35,00	30	12	0,023	0,014	18,43 €	
ZG2.5-13	13	32,50	37,50	30	12	0,026	0,017	18,74 €	
ZG2.5-14	14	35,00	40,00	30	12	0,029	0,020	18,91 €	
ZG2.5-15	15	37,50	42,50	30	12	0,032	0,023	19,08 €	
ZG2.5-16	16	40,00	45,00	30	12	0,036	0,026	19,67 €	
ZG2.5-17	17	42,50	47,50	30	12	0,039	0,030	23,05 €	
ZG2.5-18	18	45,00	50,00	36	12	0,048	0,034	23,56 €	
ZG2.5-19	19	47,50	52,50	36	12	0,052	0,038	24,33 €	
ZG2.5-20	20	50,00	55,00	36	12	0,057	0,043	24,97 €	
ZG2.5-21	21	52,50	57,50	36	12	0,061	0,047	29,44 €	
ZG2.5-22	22	55,00	60,00	36	12	0,066	0,052	30,14 €	
ZG2.5-23	23	57,50	62,50	36	12	0,071	0,057	32,74 €	
ZG2.5-24	24	60,00	65,00	36	12	0,077	0,063	35,76 €	
ZG2.5-25	25	62,50	67,50	36	12	0,082	0,068	39,72 €	
ZG2.5-26	26	65,00	70,00	36	12	0,088	0,074	41,80 €	
ZG2.5-27	27	67,50	72,50	36	12	0,094	0,080	43,89 €	
ZG2.5-28	28	70,00	75,00	45	15	0,107	0,085	44,82 €	
ZG2.5-29	29	72,50	77,50	45	15	0,113	0,091	46,00 €	
ZG2.5-30	30	75,00	80,00	45	15	0,120	0,098	47,50 €	

Dimensions in mm

DISCOUNTS

Qty	1+	6+	30+
Disc.	List	-22%	On request

Part number	Teeth Z	PCD ØP	Outside ØD	Boss ØM	Bore ØA	Weight (kg)		Price each 1 to 5	
						ZG	ZPG	ZG	ZPG
ZG2.5-31	31	77,50	82,50	45	15	0,127	0,105	55,65 €	
ZG2.5-32	32	80,00	85,00	45	15	0,134	0,112	57,11 €	
ZG2.5-33	33	82,50	87,50	45	15	0,141	0,120	59,06 €	
ZG2.5-34	34	85,00	90,00	45	15	0,149	0,127	59,84 €	
ZG2.5-35	35	87,50	92,50	45	15	0,157	0,135	61,14 €	
ZG2.5-36	36	90,00	95,00	50	17	0,169	0,142	69,89 €	
ZG2.5-37	37	92,50	97,50	50	17	0,177	0,150	70,85 €	
ZG2.5-38	38	95,00	100,00	50	17	0,186	0,159	80,76 €	
ZG2.5-39	39	97,50	102,50	50	17	0,194	0,168	82,14 €	
ZG2.5-40	40	100,00	105,00	50	17	0,203	0,177	84,14 €	
ZG2.5-41	41	102,50	107,50	50	17	0,213	0,186	86,21 €	
ZG2.5-42	42	105,00	110,00	50	17	0,222	0,195	87,52 €	
ZG2.5-43	43	107,50	112,50	50	17	0,232	0,205	88,44 €	
ZG2.5-44	44	110,50	115,00	50	17	0,244	0,217	89,43 €	
ZG2.5-45	45	112,50	117,50	50	17	0,252	0,225	90,87 €	
ZG2.5-46	46	115,00	120,00	50	17	0,262	0,235	102,00 €	
ZG2.5-47	47	117,50	122,50	50	17	0,273	0,246	104,02 €	
ZG2.5-48	48	120,00	125,00	50	17	0,283	0,257	106,82 €	
ZG2.5-49	49	122,50	127,50	50	17	0,294	0,268	109,69 €	
ZG2.5-50	50	125,00	130,00	50	17	0,306	0,279	112,64 €	
ZG2.5-51	51	127,50	132,50	50	17	0,317	0,290	113,69 €	
ZG2.5-52	52	130,00	135,00	50	17	0,329	0,302	115,22 €	
ZG2.5-53	53	132,50	137,50	50	17	0,341	0,314	116,38 €	
ZG2.5-54	54	135,00	140,00	50	17	0,353	0,326	128,37 €	
ZG2.5-55	55	137,50	142,50	50	17	0,365	0,338	133,39 €	
ZG2.5-56	56	140,00	145,00	50	17	0,378	0,351	143,18 €	
ZG2.5-57	57	142,50	147,50	65	20	0,408	0,362	145,95 €	
ZG2.5-58	58	145,00	150,00	65	20	0,421	0,375	148,23 €	
ZG2.5-59	59	147,50	152,50	65	20	0,435	0,388	150,14 €	
ZG2.5-60	60	150,00	155,00	65	20	0,448	0,402	152,69 €	
ZG2.5-62	62	155,00	160,00	65	20	0,476	0,430	172,80 €	
ZG2.5-64	64	160,00	165,00	65	20	0,504	0,458	211,35 €	
ZG2.5-65	65	162,50	167,50	65	20	0,519	0,473	226,50 €	
ZG2.5-66	66	165,00	170,00	65	20	0,534	0,488	249,10 €	
ZG2.5-68	68	170,00	175,00	65	20	0,564	0,518	260,08 €	
ZG2.5-70	70	175,00	180,00	65	20	0,596	0,549	244,57 €	
ZG2.5-71	71	177,50	182,50	65	20	0,612	0,566	292,63 €	
ZG2.5-72	72	180,00	185,00	65	20	0,628	0,582	310,34 €	
ZG2.5-73	73	182,50	187,50	65	20	0,645	0,598	321,85 €	
ZG2.5-74	74	185,00	190,00	65	20	0,661	0,615	329,46 €	
ZG2.5-75	75	187,50	192,50	65	20	0,678	0,632	308,22 €	
ZG2.5-76	76	190,00	195,00	65	20	0,695	0,649	319,57 €	
ZG2.5-78	78	195,00	200,00	65	20	0,730	0,684	348,18 €	
ZG2.5-80	80	200,00	205,00	65	20	0,766	0,720	552,02 €	

On request

↓ Gears available up to this size ↓				
ZG2.5-235	235	587,50	592,50	Dimensions: contact us
↓				On request

Dimensions in mm