


- **Operating elements**
- Working temperature: -30°C to +140°C
- Material: black phenolic plastic

square bore

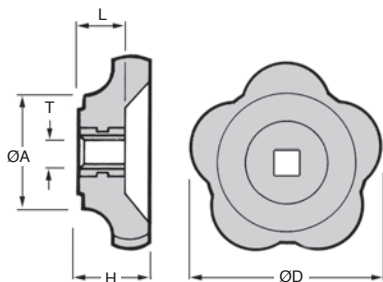

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-20%	-30%	-40%	On request

Part number	ØD	H	L	ØA	T	Stock*	Price each 1 to 9
712-051	50	18	12	22	6,5 x 6,5	✓	3,75 €
712-052	63	20	12	22	8 x 8	✓	5,12 €

*Depending on availability - Dimensions in mm

Our other products




TOC
Short swivel head,
Short



MDB-MTB-ALI
Moulded plastic bevel
gear (blue nylon), 2:1



PT880
Drive sprocket for
plate chain, Range
880

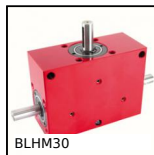

BLHM30
Right angled gearbox,
double output shafts,
up to 4.4 Nm



RBNpl
Wheel fixed with
plate, Steel - rubber



LACM_SS
Stainless steel cam
lever, Female



 
BUT
Panel stop, Panel stop



SUA4_L
Chain link, Steel



CHMBR
Reaction arm, CHM
and CHMR gear
reducers reaction arm



LSM
Stainless steel 316L
leadscrew, Stainless
steel - 1 thread



PCLA_M
Clamp lever with
threaded insert,
Plastic



H0
Crossed helical gear
crossed axis à 90°,
Steel 20NCD2

Complementary products