




Ball knobs

Smooth bored or female threads M3-M8 712


- Operating elements
- Working temperature: -30°C to +140°C
- Materials: black phenolic plastic

Moulded thread

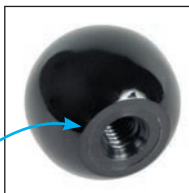


With moulded thread

Brass insert

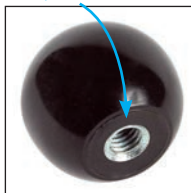

With threaded insert

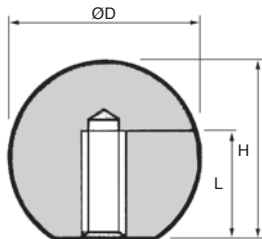

DISCOUNTS

Qty	1+	10+	20+	50+	100+
Disc.	List	-20%	-30%	-40%	On request

Part number	Thread	ØT	ØD	H	L	Stock*	Price each 1 to 9
With moulded thread							
712-001	M3		10,00	9,50	5,55	✓	1,67 €
712-002	M4		12,00	11,00	7,50	✓	1,67 €
712-003	M4		16,00	15,00	7,50	✓	1,79 €
712-004	M5		20,00	18,00	10,50	✓	1,90 €
712-005	M6		25,00	22,50	13,50	✓	2,26 €
712-006	M8		32,00	29,00	16,00	✓	2,92 €
With threaded insert							
712-007	M4		16,00	15,00	7,50	✓	2,26 €
712-008	M5		20,00	18,00	10,50	✓	2,13 €
712-009	M6		25,00	22,50	13,50	✓	2,83 €
712-010	M8		32,00	29,00	16,00	✓	4,08 €

*Depending on availability - Dimensions in mm

Our other products



Indexing plunger, weldable, Weldable - Steel



 
Asynchronous AC Motor 0.55 to 1.1kW, 0.55 to 1.1kW



Adjustable latch clamp with strike plate, Stroke from 96mm to 121,7mm



Stainless steel articulated foot Ø100, Ø 100



Tensioner pulley, For round belts



HEAVY DUTY spur gear, Steel 35NCD6



Worm and wheel set, Non hardened steel



Linear ball slide - Stainless steel balls, Rail - from 514 N to 1670...



Worm and wheel set, Machined plastic



Cap nut for foot for the food industry,



Technopolymer clamping lever - male,



Front hinge, 270°

Complementary products



Threaded spherical knob, With brass insert